


Sockets

KUN S

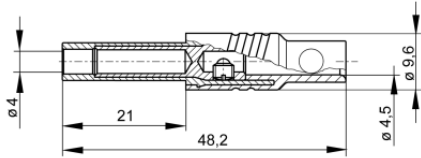

Product	KUN S
description	Safety coupling with screw connection for leads from 0.5mm ² to 1.5mm ² , outer diameter of lead max. 4,2mm Connectable with plugs 4mm and safety plugs 4mm 1000V-system, IEC 61010. Simple assembly by "Click-System".
operating instruction	BA455
article-no. / *colour	9340961xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green
drawing	
technical data	
connection	screw terminal
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	24 A
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-15 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges
 stand : November 13, 2025 6:00 PM