


Plugs

BSB 20 K

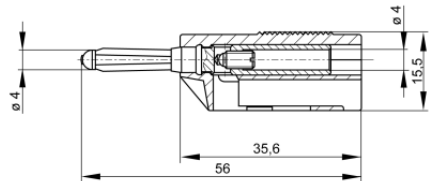

Product	BSB 20 K
description	Multiple-spring wire plug with cable gland and 4 mm socket for onward connection capability. Screw connection up to maximum cable cross-section of 2.5 mm ² and external diameter of 4 mm. Nickel-plated brass contact material.
operating instruction	BA411
article-no. / *colour	9307291xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green
drawing	
	
technical data	
connection	screw terminal
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	30 A
material plug	brass, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains