


Plugs

BUELA 30 K

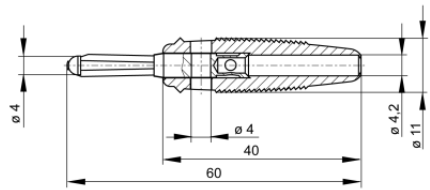

Product	BUELA 30 K
description	Multiple-spring wire plug, shatter-proof, flexible insulated sleeve with transverse hole. The tapering sleeve end also serves as kinking protection for the lead. Solder connection up to maximum cable cross-section of 2.5 mm ² . Nickel-plated brass contact material.
operating instruction	BA409
article-no. / *colour	9307271xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green ● 07 white
drawing	
	
technical data	
connection	solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	30 A
material plug	brass, nickel plated
housing material	PVC-P
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 5:59 PM