


Plugs

VST 100

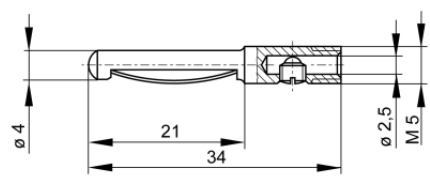

Product	VST 100
description	Fully mating connector as built-in pin, screw connection up to maximum cable cross-section of 1.5 mm². Nickel-plated brass contact material.
operating instruction	BA418
Articlenumber	930581000
drawing	
	
technical data	
connection	screw terminal
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	16 A
material plug	brass, nickel plated
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 5:59 PM