
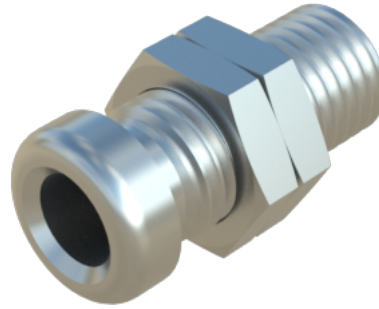


Sockets

BO 10

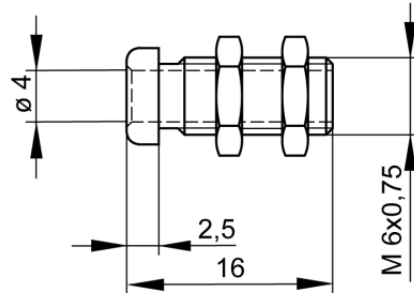

Product	BO 10
description	Bright metal 4 mm diameter nickel-plated brass socket, with M6 thread. For installation in equipment chassis and switch panels from 1.5 mm till 8.0 mm wall thickness.
operating instruction	BA403
Articlenumber	930160000
drawing	
	
technical data	
connection	M6 thread
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	16 A
material socket	brass, nickel plated
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 5:59 PM