


Crocodile clips

MA 1 Crimp

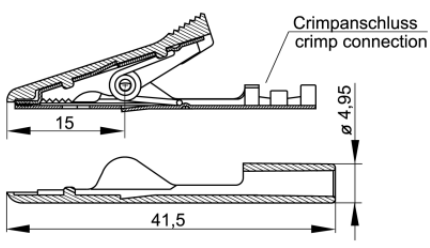

Product	MA 1 Crimp
description	Miniature alligator clip with high strength insulation and nickel-plated brass / bronze jaws. The flat part of the chuck jaws (fine wire section) allows a secure contacting, when thin wires be pinched. It is possible to clamp of flat components (soldering eyes) and wires up to a maximum diameter of 4mm. Crimp connection for 0,25mm² up to 0,5mm² wiring, with following assembly of the bottom insulating part (shim). With suitable tool to crimp (Crimping pliers CRIMPFOX-SC 1,5-M 1212725 from Phoenix Contact).
operating instruction	BA210
article-no. / *colour	9303181xx  00 black  01 red  02 blue  03 yellow  04 green  06 gray  07 white
drawing	
	
technical data	
connection	Crimp terminal 0.25 mm ² up to 0.5 mm ²
rated voltage	30 VAC / 60 VDC
rated current (consider derating curve)	8 A
material socket	bronze, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
clamping range	4 mm

2 mm system

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges
stand : November 13, 2025 5:59 PM