


Measuring leads

MAL S GG-B 200/2,5

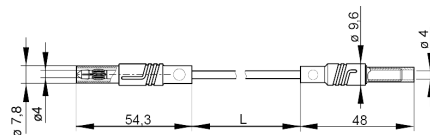

Product	MAL S GG-B 200/2,5
description	Safety adapter test lead according to IEC 61010 with 4 mm safety plug straight outlet and 4 mm safety socket on the other end. Highly flexible, double insulated stranded lead, shatter-proof grip sleeve. Built in color indicator for easy identification of insulation damages.
operating instruction	BA453
article-no. / *colour	9340471xx  00 black 01 red 02 blue 03 yellow 04 green 05 brown 06 gray 88 yellow/green
drawing	
technical data	
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	32 A
material plug	brass, nickel plated
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-15 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
cable length	200 cm
conductor size	2,5 mm ²

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges
 stand : November 13, 2025 5:59 PM