


Set

PMS 0,64

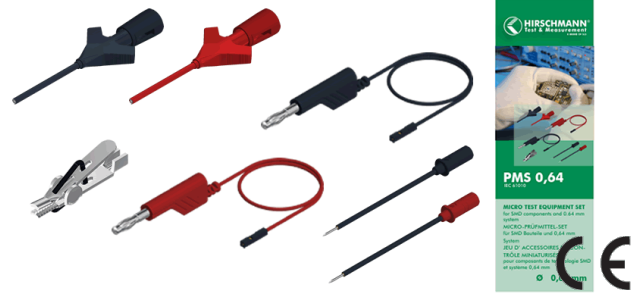

Product	PMS 0,64
description	Micro test equipment set for SMD components and 0,64 mm system. - MICRO-KLEPS Clamp-type test probe with rotating grip jaws and flexible shaft for clamping of very thin wires up to $\varnothing$ 2 mm. - MICRO-PRUEF MPS 2/0,64 FT Miniature test probe with spring-loaded stainless steel tip for sampling extremely small measuring points and SMD components. - AGF 1 Miniature alligator clip for small components up to 1 mm. Solder and crimp connection. - MAL N 4-0,64/100-0,25 Measuring lead with 4 mm plug and 4 mm socket for tower construction and 0.64 mm socket. (length: 100 cm) Please find further technical details on individual product data sheets.
Articlenumber	932959001
technical data	
scope of delivery	1 x clamp-type test probe MICRO-KLEPS black (973 972-100) 1 x clamp-type test probe MICRO-KLEPS red (973 972-101) 1 x test probe MICRO-PRUEF MPS 2/0,64 FT black (973 995-100) 1 x test probe MICRO-PRUEF MPS 2/0,64 FT red (973 995-100) 1 x miniature alligator clip AGF 1 blank (930 476-001) 1 x measuring lead MAL N 4-0,64/100-0,25 black (934 160-100) 1 x measuring lead MAL N 4-0,64/100-0,25 red (934 160-101)

stand : January 11, 2026 8:55 AM

0.64 mm system