


Sockets

PKNI 10 B

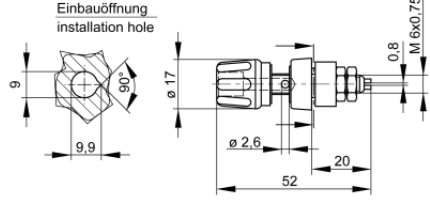

Product	PKNI 10 B
description	Pole terminal with claw edge, captive insulated head and insulated ring. 6 mm diameter nickel-plated brass threaded bolt with 2.6 mm diameter transverse hole. For insulated non-rotating installation in equipment chassis and switch panels up to 3.5 mm wall thickness.
operating instruction	BA402
article-no. / *colour	9301361xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet  88 yellow/green
drawing	
technical data	
connection	M6 thread, solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	63 A
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 5:59 PM