


Crocodile clips

AGF 20

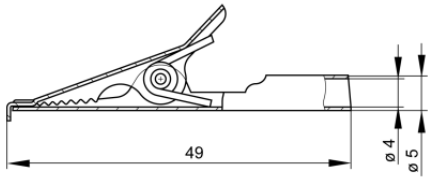

Product	AGF 20
description	Nickel-plated steel alligator clip. The special shape allows clamping of both extremely fine and thick wires. 4 mm diameter socket connection and solder connection possible. max. bolt diameter 10 mm
operating instruction	BA420
Articlenumber	930120000
drawing	
	
technical data	
connection	unsprung socket 4 mm, solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	4 A
material socket	steel, nickel plated
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C
clamping range	10 mm

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 5:59 PM