


M 1:1

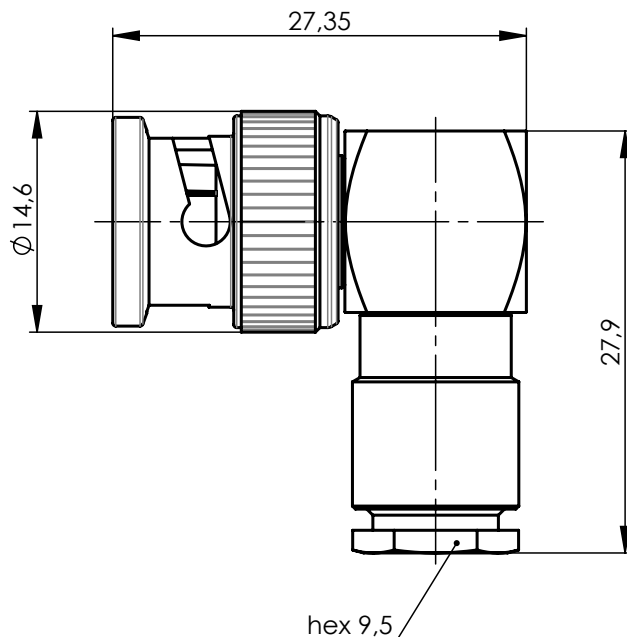

Mechanical characteristics

cable group

Mechanische Eigenschaften

Kabelgruppe

G 2: 0.6/3.7; 0.6L/3.7; 0.6L/3.7AF Draka; 3C-2V;
75022 V(0.6L/3.7) Sytronic Kabel GmbH;
75060 V(0.6/3.7) Sytronic Kabel GmbH;
8241 Belden; KX 6A; RG-59B/U;
VK95 0.6/3.7 Percon
G39: 0.8/3.7 AF Draka; 0.8/3.7C Bedea;
1505A Belden HDTV; Image 720 Argosy;
75080 AFZ 4-S Midi 0.8/3.7 Sytronic; 4505R;
Telass 80 Bedea; VPM2000 Gepco;
VK6/0.8 FRLS 0.8/3.7 Percon; CD7559 Clark

interface dimensions acc. to
assembly code

Steckgesicht nach
Montageanleitung

Components

centre contact
outer contact
other metal parts
insulator
gasket

Bauteile

Innenkontakt
Außenkontakt
sonstige Metallteile
Isolierung
Dichtung

IEC 61169-8
A06

Materials / Material

CUZn39Pb3
CUZn39Pb3, CuZn38Pb2
CuZn39Pb3, GD-ZnAl4Cu1
PTFE
silicone / Silikon, NBR

Finish / Oberfläche

NiP-Au
Cu2Ni5
Cu2Ni5, Zn/Cu6 Ni6

Environmental

RoHS compliant

Umgebung

RoHS konform

2011/65/EU

Änd./ rev. index	Änderungs-Nr. / revision code	Datum/ date	Name/ name	Datum/ date	Name/ name	Gewicht/ weight [g]
			gez./ drawn	09.03.2023	SKH	
			gepr./ appr.	13.03.2023	BJ	ca./approx.
			Maßstab/ scale	Benennung/ title		
			2:1 (1:1)	BNC Plg 90 sd/cl G2 G39 Z75 BNC Plg 90 sd/cl G2 G39 Z75		
			untol. Maße/ dim. without tolerances according to	Unterl./ doc. type	Materialnr./ material no.	
			CUG		100123515	
			Ersatz für/ replaces	PDM Nr./ pdm no. 10007568		
				Maße/ dimensions: mm		
				Original : DIN A4		
				Blatt/ sheet 1 von/ of 1		

