


AOHA21AA030 Datasheet

Product Name // Active Optical HDMI 2.1 Type A - Type A
Cable 30m

 [View Product Page](#)

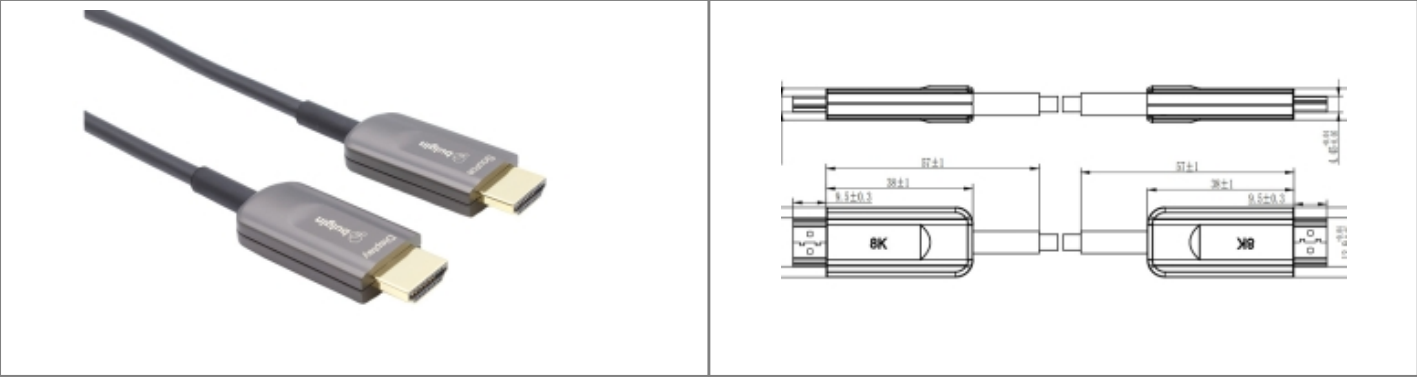

// Product Description:

- Standard PVC Jacket
- 8K@60Hz
- 48Gbps
- Low Power consumption 250mW (max)
- Hybrid type with OM3 fiber and copper wire
- 30m

// General Information:

Product Display Title:	AO Series HDMI 2.1 Type A -Type A Cable 30m
Product Family:	Data Connectors
Product Series:	AO Series Active Optical HDMI
Body Colour:	Matt Black
Body Material Type:	Metal
Cable Length:	30m
Data Cable Type:	HDMI
Fibre Mode:	Multimode
Flamability Rating:	VW-1
Function:	Active Optical HDMI Cable
Material Finish:	Matt
Max Operating Temperature:	50°C
Min Operating Temperature:	0°C
Operating Humidity:	10~80 %RH
Rohs Compliant:	Yes

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)