




GH CONNECTOR



**1.25mm Pitch/Wire-to-Board Connectors
Crimp Style and Mating Style**

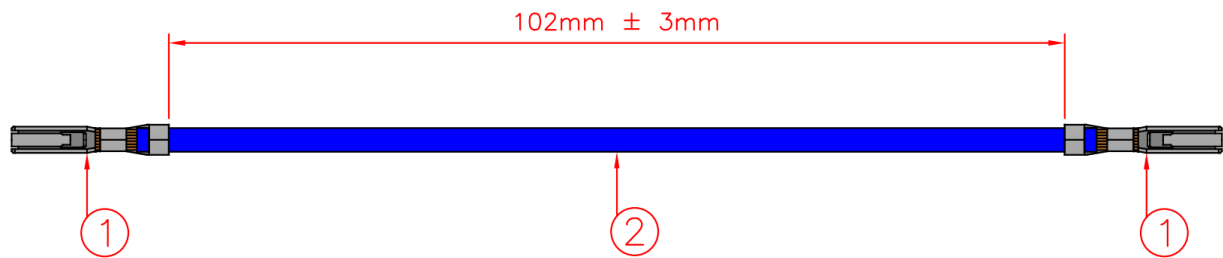

Part Number:

- AGHGH28B102

Description:

- JST Series – [GH Series](#)
- Pitch – 1.25mm
- Cable length (inside dimension) – 102mm

Material Specification:

- (1) Terminal: SSHL-002T-P0.2
- (2) Cable Type: UL1571
- (2) Cable Size: 28AWG
- (2) Cable Colour: Blue

Quality

- We trust and believe in our product. Each step of our development and manufacturing process is focused on delivering a fault-free product. JST does not compromise on quality.

Applicable Housings:

No. of Circuits	Part Number
2	GHR-02V-S
3	GHR-03V-S
4	GHR-04V-S
5	GHR-05V-S
6	GHR-06V-S
7	GHR-07V-S
8	GHR-08V-S
9	GHR-09V-S
10	GHR-10V-S
11	GHR-11V-S
12	GHR-12V-S
13	GHR-13V-S
14	GHR-14V-S
15	GHR-15V-S

Additional Information:


Alternative colour and length cables are available upon request, please contact JST for further details by e-mailing jukma@jst.co.uk



GH CONNECTOR

JST
The Quality Connection

**1.25mm Pitch/Wire-to-Board Connectors
Crimp Style and Mating Style**

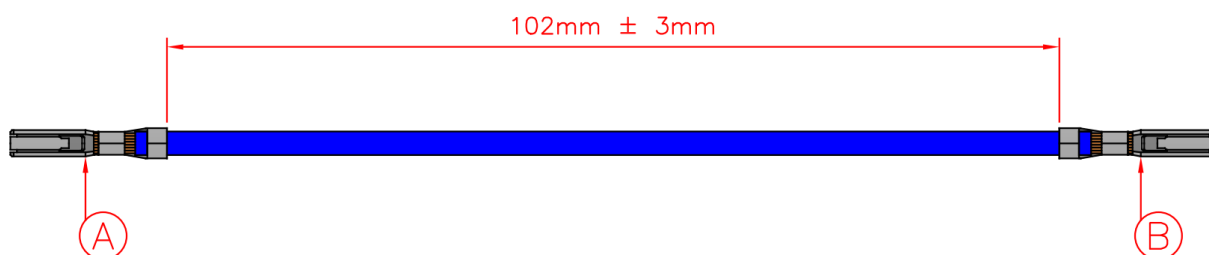

A GH GH 28 B 102

Supply Form: Assembled Wire

Terminal Part Number end A: SSHL-002T-P0.2

Terminal Part Number end B: SSHL-002T-P0.2

Cable Size: 28awg (??AWG)

Cable Colour: B (Blue), K (Black), R (Red), N (Brown), H (Grey)
O (Orange), Y (Yellow), W (White), M (Green), P (Purple), PK (Pink)

Cable Length: 102mm (????mm)

Additional Information:

Alternative colour and length cables are available upon request, please contact JST for further details by e-mailing jukma@jst.co.uk