




# GH CONNECTOR



**1.25mm Pitch/Wire-to-Board Connectors  
Crimp Style and Mating Style**

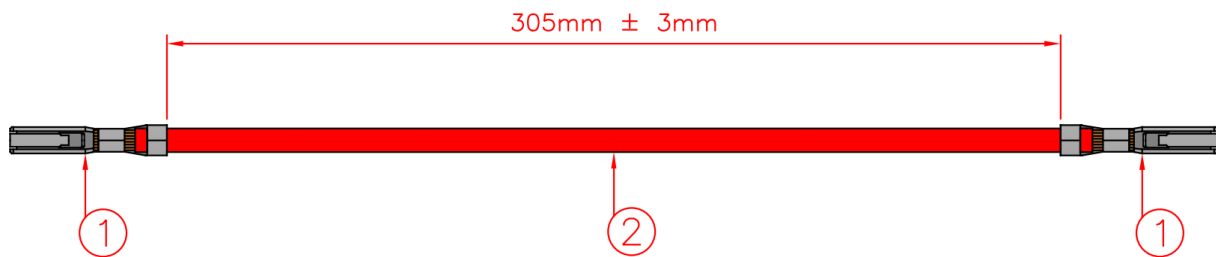

## Part Number:

- AGHGH28R305

## Description:

- JST Series – [GH Series](#)
- Pitch – 1.25mm
- Cable length (inside dimension) – 305mm

## Material Specification:

- (1) Terminal: SSL-002T-P0.2
- (2) Cable Type: UL1571
- (2) Cable Size: 28AWG
- (2) Cable Colour: Red

## Quality

- We trust and believe in our product. Each step of our development and manufacturing process is focused on delivering a fault-free product. JST does not compromise on quality.

## Applicable Housings:

| No. of Circuits | Part Number |
|-----------------|-------------|
| 2               | GHR-02V-S   |
| 3               | GHR-03V-S   |
| 4               | GHR-04V-S   |
| 5               | GHR-05V-S   |
| 6               | GHR-06V-S   |
| 7               | GHR-07V-S   |
| 8               | GHR-08V-S   |
| 9               | GHR-09V-S   |
| 10              | GHR-10V-S   |
| 11              | GHR-11V-S   |
| 12              | GHR-12V-S   |
| 13              | GHR-13V-S   |
| 14              | GHR-14V-S   |
| 15              | GHR-15V-S   |

## Additional Information:


Alternative colour and length cables are available upon request, please contact JST for further details by e-mailing [jukma@jst.co.uk](mailto:jukma@jst.co.uk)



# GH CONNECTOR

**JST**  
The Quality Connection

**1.25mm Pitch/Wire-to-Board Connectors  
Crimp Style and Mating Style**

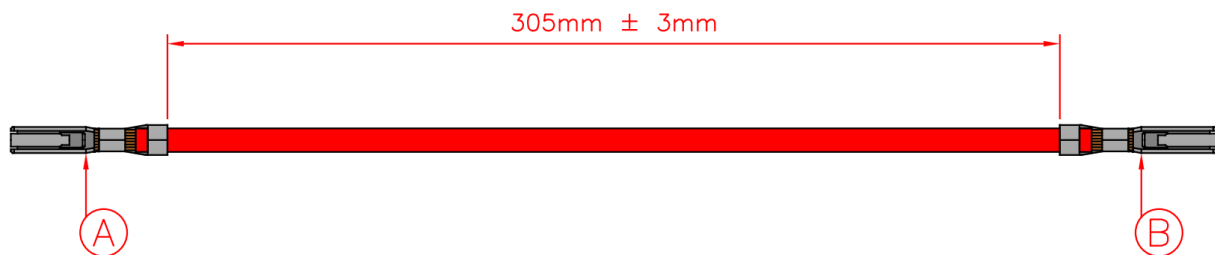

**A GH GH 28 R 305**

**Supply Form:** Assembled Wire

**Terminal Part Number end A:** SSHL-002T-P0.2

**Terminal Part Number end B:** SSHL-002T-P0.2

**Cable Size:** 28awg (??AWG)

**Cable Colour:** B (Blue), K (Black), R (Red), N (Brown), H (Grey)  
O (Orange), Y (Yellow), W (White), M (Green), P (Purple), PK (Pink)

**Cable Length:** 305mm (????mm)

## Additional Information:

Alternative colour and length cables are available upon request, please contact JST for further details by e-mailing [jukma@jst.co.uk](mailto:jukma@jst.co.uk)