




SPECIFICATION CONTROL DRAWING Crystal Resonator

FREQUENCY

50.000000MHz

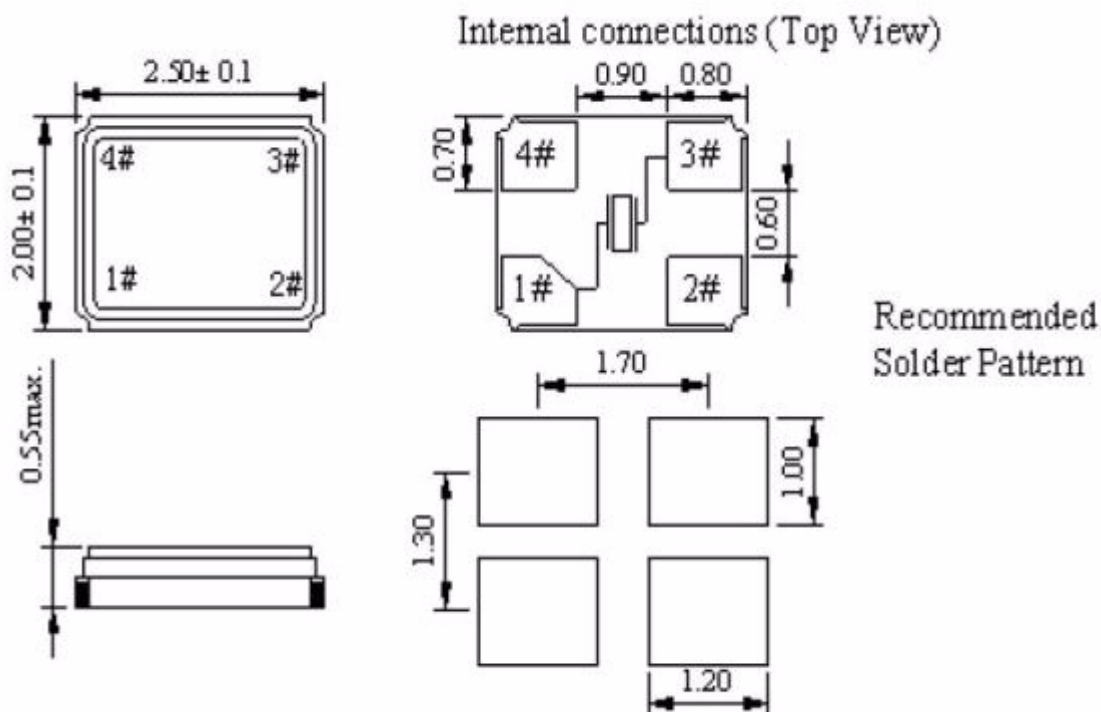

Holder Style	25x2x05 4-pad
Mode	Fundamental
Adjustment Tolerance	± 10PPM at 25°C
Temperature Stability	± 15 PPM
Operating Temp. Range	-30°C to +85°C
Load Capacitance	16 pF
ESR	60 Ohm
Ageing	+/-2ppm first Year Max
Marking	AEL50

Amdt Date	Change Note	AEL Code
18 APR 08	Temp stability and op temp range amended	X50M000000S005
		Issue Ref B