




809 950  
809 962



Connectors



Type	VON 10	VON 20	VON 30
Order no.	930 045- . . . (see colour index below)*	930 046- . . . (see colour index below)*	930 047- . . . (see colour index below)*
Quantity boxed	100 each	100 each	100 each
Dimensions			

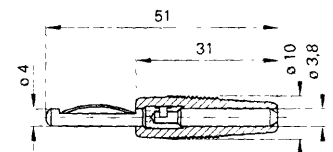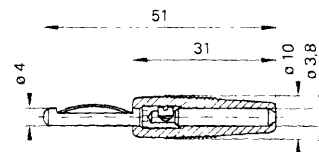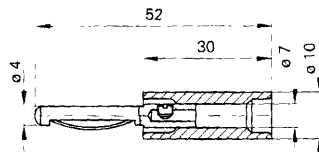

Description	VON 10	VON 20	VON 30
	Fully mating connector, polystyrene insulating sleeve, screwed on. <b>Screw connection</b> up to a maximum conductor cross-section of 1.5 mm <sup>2</sup> Nickel-plated brass contact	Fully mating connector, shatter-proof flexible insulating sleeve. The sleeve narrows at the end to prevent the cable from buckling <b>Screw connection</b> up to a maximum conductor cross-section of 1.5 mm <sup>2</sup> . Nickel-plated brass contact	Fully mating connector, shatter-proof flexible insulating sleeve. The sleeve narrows at the end to protect the cable against buckling <b>Solder connection</b> up to a maximum conductor cross-section of 1.5 mm <sup>2</sup> Nickel-plated brass contact

Technical data

Type of connection	screw	screw	solder
Continuous load current	16 A	16 A	16 A
Volume resistance (max.)	3 mΩ	3 mΩ	3 mΩ
Permissible temperature range	-25 °C . . . +70 °C	-25 °C . . . +70 °C	-25 °C . . . +70 °C
Colour index*	black	-100	-100
	red	-101	-101
	blue	-102	-102
	yellow	-103	-103
	green	-104	-104
	assorted cirs.	930 271-000 (VON 10 F)	

Version VON 10 F in assorted colours is made up of 20 connectors in each of the colours black, red, blue, yellow and green

4 mm dia.  
laboratory equipment