



Wiha. Premium Tools  
for Professionals.

Wiha PicoFinish. The Specialist for Precision Applications.



*The soft material of the handle, together with the rotating cap, enables optimum and sensitive twisting.*



*The clear marking of the drive on the rotating cap provides easy and fast identification of the required screwdriver.*




The Wiha PicoFinish screwdrivers are predestined for high-precision work, predominantly with electro-technical and precision components.

The octagonal rapid-rotation zone at the front of the handle allows rapid twisting.

The extraordinarily easy-to-twist rotating cap permits the delicate turning of fine screws with just one hand.

#### PicoFinish Advantages:

- Special soft plastic material assures comfortable, delicate work
- Ideal for fine adjustments in electronic assembly work and precision applications, as well as for hobby use and model making
- Clear marking of the drive on the rotating cap provides easy and fast identification of the required screwdriver
- Convex handle end allows the transmission of a controlled high torque to powerfully tighten or loosen the screw head
- Palm saving rotating cap with a large surface for the fingers makes incremental adjustment easy
- Wiha ChromeTop-finish on tip for a perfect fit every time

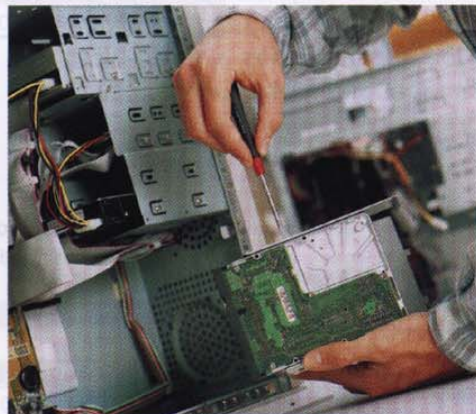



Wiha. Premium Tools  
for Professionals.

**Wiha PicoFinish. The Specialist for Precision Applications.**

**For Hexagon Socket Screws.**



**263 P Hex Screwdriver.**  
**With rotating cap and rapid-turning zone.**  
 Blade: High quality chrome-vanadium-molybdenum steel, through hardened, chrome-plated.  
 Wiha ChromTop finish on tip for a perfect fit every time.  
 Handle: Wiha PicoFinish handle for rapid rotation.  
 Application: Ideal for high-precision work with electro-technical and precision components.

Order-No.	●	→	→	→	→
00519 1	0.7	40	140	18	10
00520 7	0.9	40	140	18	10
00521 4	1.3	40	140	18	10
00522 1	1.5	50	150	18	10
00523 8	2	50	150	18	10
00524 5	2.5	60	160	18	10
00525 2	3	60	160	18	10

**263 P Inch Hex Screwdriver.**  
**With rotating cap and rapid-turning zone. Inch sizes.**

Order-No.	●	→	→	→	→
00519 1	0.028"	40	140	18	10
00520 7	0.035"	40	140	18	10
00521 4	0.050"	40	140	18	10
00526 9	1/16"	50	150	18	10
00523 8	5/64"	50	150	18	10
00528 3	3/32"	60	150	18	10
00530 6	7/64"	60	150	18	10
00527 6	1/8"	60	150	18	10

**For Hexagon Socket Screws.**



**264 P Ballpoint Hex Screwdriver.**  
**With rotating cap and rapid-turning zone.**  
 Blade: High quality chrome-vanadium-molybdenum steel, through hardened, chrome-plated.  
 Wiha ChromTop finish on tip for a perfect fit every time.  
 Handle: Wiha PicoFinish handle for rapid rotation.  
 Application: Ideal for high-precision work with electro-technical and precision components.  
 Extra: Ballpoint allows up to 25 degree entry angle to fastener.

Order-No.	●	→	→	→	→
00531 3	1.3	40	140	18	10
00532 0	1.5	50	150	18	10
00533 7	2	50	150	18	10
00534 4	2.5	60	160	18	10
00535 1	3	60	160	18	10

**264 P Inch Ballpoint Hex Screwdriver.**  
**With rotating cap and rapid-turning zone. Inch sizes.**

Order-No.	●	→	→	→	→
00531 5	0.050"	40	120	18	10
00537 5	1/16"	50	150	18	10
00541 2	5/64"	50	150	18	10
00539 9	3/32"	50	150	18	10
00542 9	7/64"	60	160	18	10
00538 2	1/8"	60	160	18	10
00543 6	9/64"	60	160	18	10
00540 5	5/32"	60	160	18	10