

1700 & 1750 Lever Switches

16A 250Vac Single & Double Pole



16(4)A 250Vac T85

Inrush 36A to EN61058-1

20A 28Vdc

UL 20A 250V Non Ind SP

UL 16A 250V Non Ind DP

UL CSA (2 pos types) 250V 1hp, 125V ½hp

UL CSA (3 pos types) 250 ½hp, 125V ¼hp

CSA 16A 250V Non Ind

UL 85°, file E45221

CSA file LR10990

UL and CSA N/A momentary types

Examples



C1700HO---




C1750O---

Selective, A or B or C, and Off, A, A+B circuits at 5 amp also available.

3mm contact gap except where marked μ .


Order Format

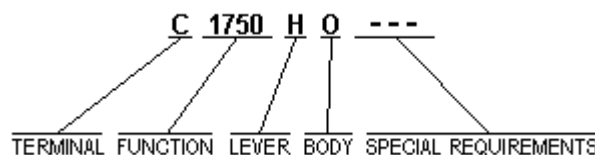


Product Options

Dimensions

Single Pole (Nylon lever)

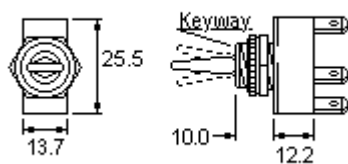

Double Pole (Nylon lever)

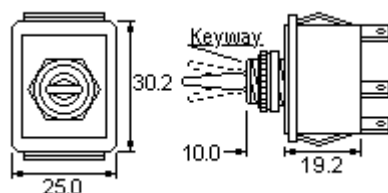

Double Pole (Metal lever)

