

PLS-020A-3

World's smallest magnetic Level Sensor




Electrical Characteristics

@25°C


Contact form		A
Contact material		Ru
Contact rating max.	W / VA	10
Switching current max.	A	0.7
Carry current max.	A	1.0
Switching voltage max.	VDC	180
	VAC	130
Breakdown voltage min.	VDC	200

Dimensions

in mm

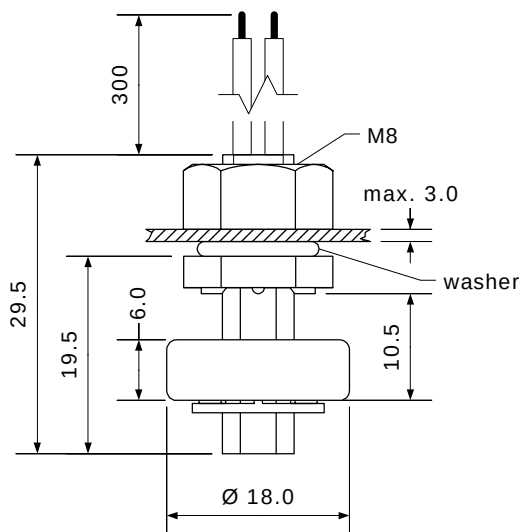

Operating diagram

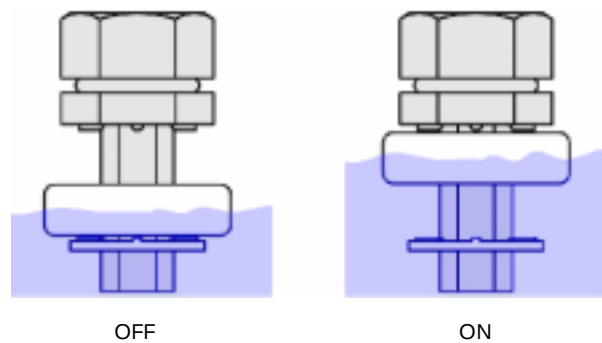

Temperature Range

Operating temperature	°C	-20 to +80
Storage temperature	°C	-30 to +80

PLS-020A-3
World's smallest
magnetic Level Sensor



Material

Use in

Polypropylene (PP)	Water, dilute acids
---------------------------	---------------------

Remarks

- When mounted near ferromagnetic parts switching points may vary

Packing

- Packing unit 10 pcs. per plastic bag, protected accordingly

Customized types available.