



Lithium

Pin Type CR435 Specification

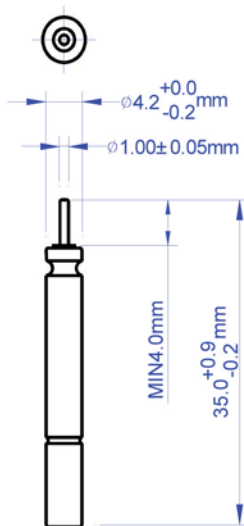


Nominal Voltage		3.0V
Dimensions (Max.)	Diameter	4.2mm
	Height	35.9mm
Ref.Weight		0.95g
Nominal Capacity		50mAh
Continuous Standard Load		1.0mA
Cut off Voltage		2.0V
Maximum Continuous Discharge Current		5.0mA
Maximum Pulse Discharge Current		--
Operating Temperature		-20 ~ 60°C


Discharge Characteristics

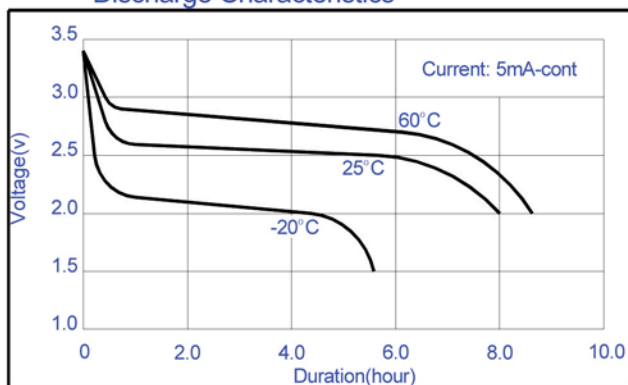


Discharge Characteristics

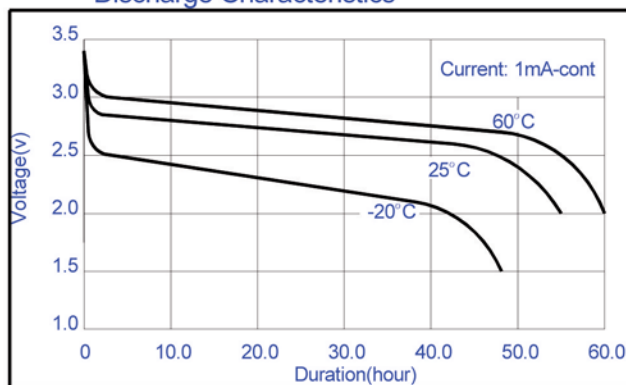

Discharge Characteristics

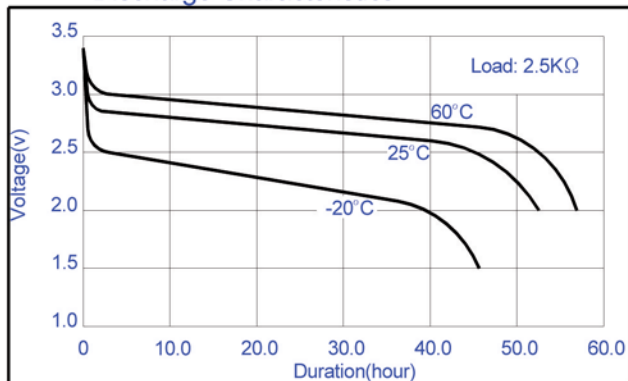

Discharge Characteristics

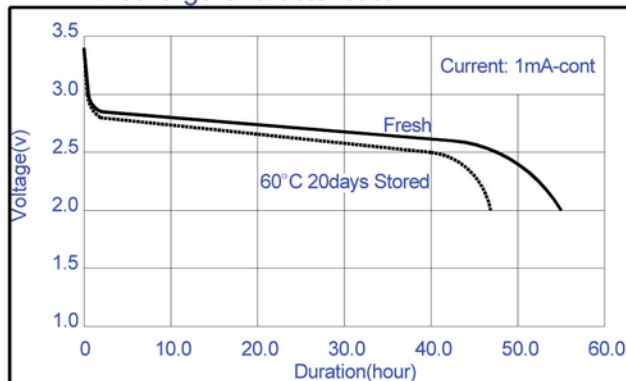

WARNING:

- Do not charge, disassemble, heat above 100°C or incinerate.
- Do not mix fresh batteries and used batteries or other types of battery together.
- Do not short circuit.