

## LED machine luminaire





**SPOT LED 003 - MCXFL 3 S**

connected load  
 fitted with  
 work equipment  
 mains lead  
 luminaire body  
 material  
 surface  
 weight (net)  
 fastening  
  
 technology  
 usage  
 lamp cover  
 system of protection  
 class of protection  
 colour luminaire body  
 special features  
 article no.

24 V; AC/DC  
 1 x LED lamp 10 W  
 without  
 approx. 3 m with free stranded wires  
  
 aluminium  
 anodized  
 approx. 0,7 kg  
 screw-down flange~magnetic base (accessory)~table  
 clamp (accessory)~wall bracket (accessory)  
 switchable  
 without switch  
 glass screen  
 IP 67  
 III  
 black  
 Spot with a 10° angle of radiation,  
 112459004

Emin: 58 lx  
 Em: 1604 lx  
 Emax: 13406 lx

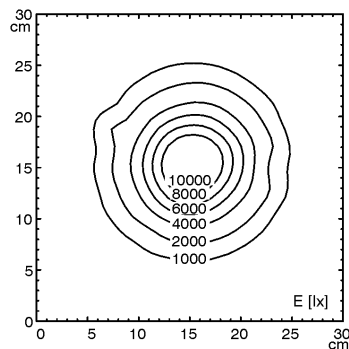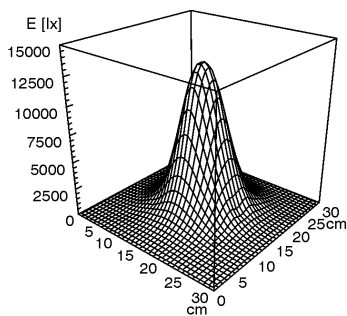

measuring conditions: d=50cm

