


71 KNIPEX-"CoBolt", Compact Bolt Cutters (Lever Action Center Cutters)

patented



71 01 200

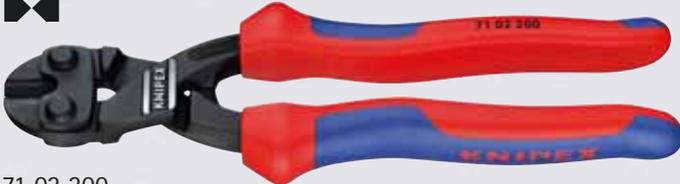

71 02 200



71 11 200



Model 71 11 200: with opening spring and stirrup lock

- ▶ with precision blades for soft, hard and piano wire
- ▶ cuts material like bolts, nails, rivets, etc. up to 5.2 mm dia.
- ▶ exceptional cutting performance with minimum effort because of new lever action design
- ▶ cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- ▶ forged
- ▶ Chrome Vanadium electric steel, oil-hardened and tempered

Model 71 31 200:

- ▶ the recess in the blade allows easier cutting of thicker wires, e. g. for false ceilings



KNIPEX special

The KNIPEX Compact Bolt Cutter is a "clever muscle man". The newly designed lever action mechanism guarantees an extremely favourable lever ratio with low friction. The cutting performance is 20 times higher than the handforce applied.

Requires 61% less effort.

Cutting a piano wire of 2.0 mm dia. with the KNIPEX-"CoBolt" requires handforce of 192 N (19.2 kp) instead of 499 N (49.9 kp) with a High Leverage Diagonal Cutter of the same length.



Article-No.	EAN-Code	Style	Head	Handles	Cutting capacities				g
					Ø mm	Ø mm	Ø mm	Ø mm	
71 01 200	010067	0	atramentized	plastic coated	6.0	5.2	4.0	3.6	340
71 02 200	047056		atramentized	with two-colour dual component handles	6.0	5.2	4.0	3.6	380
71 11 200	022312	1	atramentized	plastic coated	6.0	5.2	4.0	3.6	350
71 31 200	030805	3	atramentized	plastic coated	6.0	5.2	4.0	3.6	340



71 31 200: The recess near the joint keeps thicker wires to be cut in a secure position, ensuring optimum application of cutting performance

72 Diagonal Cutter for fibre optics (Glass Fibre Cable)



72 51 160



- ▶ specially developed for cutting glass fibre cable (fibre optics)
- ▶ cutting face flush ground
- ▶ cutting edges additionally induction hardened
- ▶ with opening spring
- ▶ Vanadium electric steel, oil-hardened and tempered

Article-No.	EAN-Code	Head	Handles	g
72 51 160	028031	polished	plastic coated	170