



► Product Group 8**Page**

Display boards	8.03
Assortment boxes with tubular cable lugs and compression cable lugs	8.04
Pocket boxes with cable end-sleeves	8.05 – 8.06
Assortment boxes with cable end-sleeves	8.07 – 8.09
Assortment boxes with insulated terminals	8.10 – 8.11
Assortment boxes, empty	8.12 – 8.20

DISPLAY BOARDS VK

with hooks



8

Part No. VK 1
dimensions:
220 x 100 x 40 cm

Part No. VK 2
dimensions:
220 x 120 x 40 cm

Part No. VK 3
dimensions:
220 x 140 x 40 cm

Contents and
other dimensions
on request.

ASSORTMENT BOX WITH TUBULAR CABLE LUGS

Steel carrying case, with lock and handle

SK 65 B

contents: tubular cable lugs

25 pcs				20 pcs		
1 R/6	6 mm ²	M 6		5 R/8	35 mm ²	M 8
1 R/8	6 mm ²	M 8		5 R/10	35 mm ²	M 10
2 R/6	10 mm ²	M 6		6 R/10	50 mm ²	M 10
2 R/8	10 mm ²	M 8		6 R/12	50 mm ²	M 12
3 R/8	16 mm ²	M 8				
3 R/10	16 mm ²	M 10				
4 R/8	25 mm ²	M 8				
4 R/10	25 mm ²	M 10				

and 1 crimping tool K 05

dimensions: 400 x 250 x 50 mm

Case also available without contents. Part No. SK 65 L



ASSORTMENT BOX WITH COMPRESSION CABLE LUGS DIN 46235

Steel carrying case, with lock and handle

SK 50 B

contents: compression cable lugs DIN 46235

50 pcs				20 pcs		
101 R/5	6 mm ²	M 5		105 R/8	35 mm ²	M 8
101 R/6	6 mm ²	M 6		105 R/10	35 mm ²	M 10
102 R/5	10 mm ²	M 5				
102 R/6	10 mm ²	M 6		15 pcs		
				106 R/10	50 mm ²	M 10
25 pcs				106 R/12	50 mm ²	M 12
103 R/8	16 mm ²	M 8				
103 R/10	16 mm ²	M 10				
104 R/8	25 mm ²	M 8				
104 R/10	25 mm ²	M 10				

and 1 crimping tool K 05 D

dimensions: 400 x 250 x 50 mm

Case also available without contents. Part No. SK 65 L



POCKET BOXES WITH NON INSULATED CABLE END-SLEEVES

ST 21 B

contents:
cable end-sleeves non insulated
1000 pcs

71 S/6 v 0.5 mm²

500 pcs

71/6 v 0.75 mm²

72 S/6 v 1 mm²

72/7 v 1.5 mm²

73/7 v 2.5 mm²

Also available without contents
Part No. ST 21 L



ST 22 B

contents:
cable end-sleeves non insulated
200 pcs

74/9 v 4 mm²

100 pcs

75/12 v 6 mm²

70 pcs

76/12 v 10 mm²

77/12 v 16 mm²

Also available without contents
Part No. ST 22 L



ST 23 B

contents:
cable end-sleeves non insulated
1000 pcs

69/5 v 0.25 mm²

70/5 v 0.34 mm²

71 S/6 v 0.5 mm²

500 pcs

71/6 v 0.75 mm²

72 S/6 v 1 mm²

Also available without contents
Part No. ST 23 L



ASSORTMENT OF POCKET BOXES WITHOUT CONTENTS

ST 5 L



POCKET BOX WITH INSULATED TWIN CABLE END-SLEEVES

ST 15 B

contents:
insulated twin cable end-sleeves
50 pcs

870/8 grey 2 x 0.75 mm²

871/8 red 2 x 1 mm²

872/8 black 2 x 1.5 mm²

873/10 blue 2 x 2.5 mm²

Also available without contents
Part No. ST 15 L



POCKET BOXES WITH PRE-INSULATED CABLE END-SLEEVES

ST 1 B

contents: cable end-sleeves pre-insulated 50 pcs		
169/O	orange	0.5 mm ²
100 pcs		
170/W	white	0.75 mm ²
171/G	yellow	1 mm ²
172/RO	red	1.5 mm ²
50 pcs		
173/B	blue	2.5 mm ²

Also available without contents
Part.-No. ST 1 L

ST 11 B

contents: cable end-sleeves DIN 46228, part 4, pre-insulated 50 pcs		
469/8	white	0.5 mm ²
100 pcs		
470/8	grey	0.75 mm ²
471/8	red	1 mm ²
472/8	black	1.5 mm ²
50 pcs		
473/8	blue	2.5 mm ²

Also available without contents
Part No. ST 11 L

ST 31 B

contents: cable end-sleeves pre-insulated 50 pcs		
169/8	white	0.5 mm ²
100 pcs		
170/8	blue	0.75 mm ²
171/8	red	1 mm ²
172/8	black	1.5 mm ²
50 pcs		
173/8	grey	2.5 mm ²

Also available without contents
Part No. ST 31 L



ST 2 B

contents: cable end-sleeves pre-insulated 50 pcs		
174/GR	grey	4 mm ²
20 pcs		
175/S	black	6 mm ²
176/E	ivory	10 mm ²
10 pcs		
177/GR	green	16 mm ²

Also available without contents
Part No. ST 2 L

ST 12 B

contents: cable end-sleeves DIN 46228, part 4, pre-insulated 50 pcs		
474/10	grey	4 mm ²
20 pcs		
475/12	yellow	6 mm ²
476/12	red	10 mm ²
10 pcs		
477/12	blue	16 mm ²

Also available without contents
Part No. ST 12 L

ST 32 B

contents: cable end-sleeves pre-insulated 50 pcs		
174/10	orange	4 mm ²
20 pcs		
175/12	green	6 mm ²
176/12	brown	10 mm ²
10 pcs		
177/12	ivory	16 mm ²

Also available without contents
Part No. ST 32 L



ST 3 B

contents: cable end-sleeves pre-insulated 30 pcs		
167/H	light blue	0.25 mm ²
168/T	turquoise	0.34 mm ²
169/O	orange	0.5 mm ²
170/W	white	0.75 mm ²
171/G	yellow	1 mm ²

Also available without contents
Part No. ST 3 L

ST 13 B

contents: cable end-sleeves DIN 46228, part 4, pre-insulated 30 pcs		
167/H	light blue	0.25 mm ² *
168/T	turquoise	0.34 mm ² *
469/8	white	0.5 mm ²
470/8	grey	0.75 mm ²
471/8	red	1 mm ²

* Not standardized

Also available without contents
Part No. ST 13 L

ST 33 B

contents: cable end-sleeves pre-insulated 30 pcs		
167/6	light yellow	0.25 mm ²
168/6	light green	0.34 mm ²
169/8	white	0.5 mm ²
170/8	blue	0.75 mm ²
171/8	red	1 mm ²

Also available without contents
Part No. ST 33 L



ASSORTMENT BOXES WITH CABLE END-SLEEVES

Steel carrying case

SK 30 B

contents: cable end-sleeves non insulated

1000 pcs

71/6 v 0.75 mm²

72 S/6 v 1 mm²

72/7 v 1.5 mm²

73/7 v 2.5 mm²

and 1 crimping tool K 48

dimensions: 200 x 140 x 40 mm

Case also available without contents

Part No. SK 30 L



SK 32 B

contents: cable end-sleeves non insulated

1000 pcs

71/6 v 0.75 mm²

72 S/6 v 1 mm²

72/7 v 1.5 mm²

and 1 crimping tool K 3

dimensions: 285 x 155 x 45 mm

Case also available without contents

Part No. SK 32 L

500 pcs

73/7 v 2.5 mm²

74/9 v 4 mm²

75/10 v 6 mm²

250 pcs

76/18 v 10 mm²

150 pcs

77/18 v 16 mm²



SK 45 B

contents: cable end-sleeves

DIN 46228, part 4, pre-insulated

300 pcs

470/8 grey 0.75 mm²

471/8 red 1 mm²

472/8 black 1.5 mm²

and 1 crimping tool K 48

dimensions: 200 x 140 x 40 mm

Case also available without contents

Part No. SK 30 L

200 pcs

473/8 blue 2.5 mm²



ASSORTMENT BOXES WITH PRE-INSULATED CABLE END-SLEEVES

Steel carrying case

SK 47 B

contents: cable end-sleeves

DIN 46228, part 4, pre-insulated
200 pcs

470/8 grey 0.75 mm²

471/8 red 1 mm²

472/8 black 1.5 mm²

473/8 blue 2.5 mm²

and 1 crimping tool K 3

dimensions: 285 x 155 x 45 mm

Case also available

without contents

Part No. SK 32 L

100 pcs

474/10 grey 4 mm²

475/12 yellow 6 mm²

476/18 red 10 mm²

50 pcs

477/18 blue 16 mm²



ASSORTMENT BOXES WITH PRE-INSULATED CABLE END-SLEEVES

Plastic carrying case

SK 30/3 S

contents: pocket boxes with cable
end-sleeves pre-insulated

DIN 46228, part 4

100 pcs

469/8 white 0.5 mm²

470/8 grey 0.75 mm²

471/8 red 1 mm²

472/8 black 1.5 mm²

and 1 crimping tool K 30/3

dimensions: 275 x 230 x 83 mm

50 pcs

473/8 blue 2.5 mm²

474/10 grey 4 mm²

30 pcs

475/12 yellow 6 mm²

476/12 red 10 mm²



ASSORTMENT BOX WITH PRE-INSULATED CABLE END-SLEEVES AND TWIN CABLE END-SLEEVES

Steel carrying case

SK 43 B

contents: cable end-sleeves and
twin cable end-sleeves pre-insulated
500 pcs

470/8	grey	0.75 mm ²
471/8	red	1 mm ²
472/8	black	1.5 mm ²

300 pcs

473/8	blue	2.5 mm ²
-------	------	---------------------

200 pcs

870/8	grey	2 x 0.75 mm ²
871/8	red	2 x 1 mm ²
872/8	black	2 x 1.5 mm ²

100 pcs

873/10	blue	2 x 2.5 mm ²
--------	------	-------------------------


and 1 stripping tool K 41

as well as 1 crimping tool K 32

dimensions: 370 x 210 x 40 mm

Case also available without contents

Part No. SK 43 L

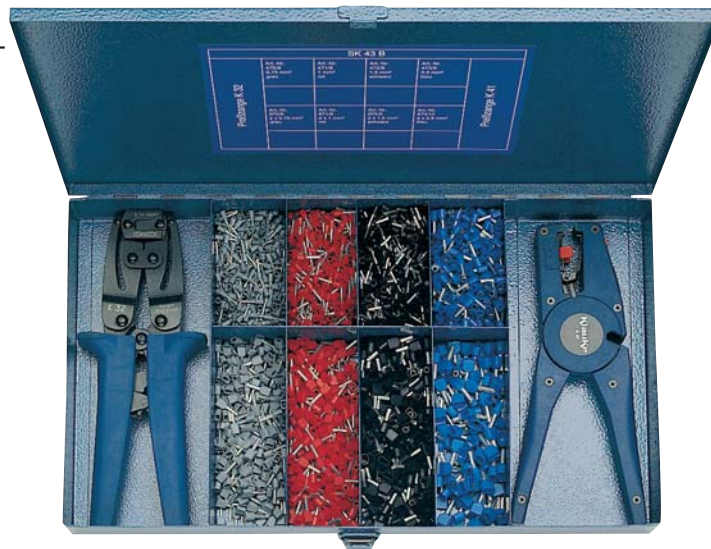

ASSORTMENT BOX WITH PRE-INSULATED CABLE END-SLEEVES

Plastic carrying case

SK 30/3 P

contents: pocket boxes with cable end-sleeves
pre-insulated
DIN46228, part 4

400 pcs

469/8	white	0.5 mm ²
470/8	grey	0.75 mm ²

400 pcs

471/8	red	1 mm ²
472/8	black	1.5 mm ²

200 pcs

473/8	blue	2.5 mm ²
474/10	grey	4 mm ²

100 pcs

475/12	yellow	6 mm ²
476/12	red	10 mm ²

and 1 stripping tool K 43/2

as well as crimping tool K 30/3

dimensions: 395 x 295 x 106 mm



ASSORTMENT BOXES WITH PRE-INSULATED TERMINALS

Steel carrying case

MK 210 B

contents: terminals pre-insulated

50 pcs
620 C / 4
630 / 5
710

and 1 crimping tool K 10
dimensions: 250 x 155 x 40 mm
weight: approx. 1.450 kg

25 pcs
650 / 5

Case also available without contents
Part No. MK 210 L



MK 220 B

contents: terminals pre-insulated

50 pcs
620 / 5
630 / 5
620 C / 4
630 C / 4
705
710

and 1 crimping tool K 10
dimensions: 370 x 160 x 40 mm
weight: approx. 2.150 kg

Case also available without contents
Part No. MK 220 L

25 pcs
650 / 5
715



MK 230 B

contents: terminals pre-insulated

50 pcs
620 / 4
620 / 5
620 / 6
630 / 4
630 / 5
630 / 6
670

680
705
710
730
830
620 C / 4
630 C / 4

25 pcs
715
700
650 / 5
650 / 6
650 C / 6

and 1 crimping tool K 10

dimensions: 366 x 230 x 51 mm
weight: approx. 3.700 kg

Case also available without contents
Part No. MK 230 L



ASSORTMENT BOXES WITH TERMINALS PRE-INSULATED

Plastic carrying case

SK 82 S

contents: pocket boxes with terminals pre-insulated

20 pcs

620/4

620/5

670

720

20 pcs

630/4

630/5

680

730

and 1 crimping tool K 82

dimensions: 275 x 230 x 83 mm



SK 82 P

contents: pocket boxes with terminals pre-insulated

50 pcs

620/4

620/5

670

720

20 pcs

650/5

650/6

700

715

50 pcs

630/4

630/5

680

730

20 pcs

620C/4

710

705

630C/4

and 1 automatic wire stripping tool K 41
as well as 1 crimping tool K 82

dimension: 395 x 295 x 106 mm



STEEL CARRYING CASES **EMPTY**

SK 30 L

for optional storage of crimping tools
type K 1, K 4, K 46 and K 48.
4 additional compartments.
With lock.

dimensions: 200 x 140 x 40 mm
weight: approx. 1.200 kg



SK 32 L

for optional storage of crimping tools
type K 3 and K 35.
8 additional compartments.
With lock.

dimensions: 285 x 155 x 45 mm
weight: approx. 1.300 kg



STEEL CARRYING CASES **EMPTY**

SK 4 L

for optional storage of crimping tools
type K 02, K 2, K 16, K 25, K 28 and K 29.
6 additional compartments.
With lock.

dimensions: 370 x 160 x 40 mm
weight: approx. 1.400 kg



SK 43 L

for storage of crimping tool type 32 and
stripping tool K 40.
8 additional compartments.
With lock.

dimensions: 370 x 210 x 40 mm
weight: approx. 1.900 kg



MK 55

for storage of crimping tool type K 50.
8 additional compartments for dies.
With lock.

dimensions: 245 x 130 x 37 mm
weight: approx. 0.700 kg



STEEL CARRYING CASES **EMPTY**

MK 210 L

for storage of crimping tool type K 10.
4 additional compartments.
With lock.

dimensions: 250 x 155 x 40 mm
weight: approx. 0.950 kg



MK 220 L

for storage of crimping tool type K 10.
8 additional compartments.
With lock.

dimensions: 370 x 160 x 40 mm
weight: approx. 1.350 kg



MK 230 L

for storage of crimping tool type K 10.
19 additional compartments.
With lock and handle.

dimensions: 366 x 230 x 51 mm
weight: approx. 2.350 kg



STEEL CARRYING CASES

EMPTY

SK 65 L

for storage of crimping tools type K 05.
12 additional compartments.
With lock and handle.

dimensions: 400 x 250 x 50 mm
weight: approx. 2.300 kg



SK 95 L

for storage of crimping tools type K 08.
6 additional compartments.
With lock and handle.

dimensions: 550 x 300 x 65 mm
weight: approx. 3.700 kg



SK 120 L

for optional storage of crimping tools type K 06, K 09
or cable cutter K 105/1.
8 additional compartments.
With lock and handle.

dimensions: 680 x 265 x 65 mm
weight: approx. 4.700 kg



STEEL CARRYING CASES **EMPTY**

MK 18

for storage of crimping tool K 18.
34 additional compartments for dies.
With lock and handle.

dimensions: 605 x 300 x 50 mm
weight: approx. 4.600 kg



MK 22

for storage of crimping tool K 22.
17 additional compartments for dies.
With lock and handle.

dimensions: 600 x 220 x 65 mm
weight: approx. 3.500 kg



STEEL CARRYING CASES **EMPTY**

MK 60/18

for storage of crimping tool HK 60/18
and 8 pairs of crimping dies.
With lock and handle.

dimensions: 615 x 270 x 68 mm
weight: approx. 3.000 kg



MK 60/22

for storage of crimping tool HK 60/22
and 17 pairs of crimping dies.
With lock and handle.

dimensions: 615 x 270 x 68 mm
weight: approx. 3.000 kg



MK 60 VP

for storage of crimping tools
HK 60 VP resp. HK 60 VP/FT.
With lock and handle.

dimensions: 615 x 270 x 68 mm
weight: approx. 3.000 kg



STEEL CARRYING CASES EMPTY

MK 60 UNV

for storage of Universal Tool HK 60 UNV,
as well as adapters and dies.
With lock and handle.

dimensions: 615 x 27 x 68 mm
weight: approx. 3.000 kg



MK 120/25

for storage of crimping tool type HK 120/25
and 18 pairs of crimping dies.
With lock and handle.


dimensions: 715 x 270 x 88 mm
weight: approx. 3.600 kg



MK 120/42

for storage of the crimping tool HK 120/42
and 18 pairs of crimping dies.
With lock and handle.

dimensions: 715 x 270 x 88 mm
weight: approx. 3.900 kg

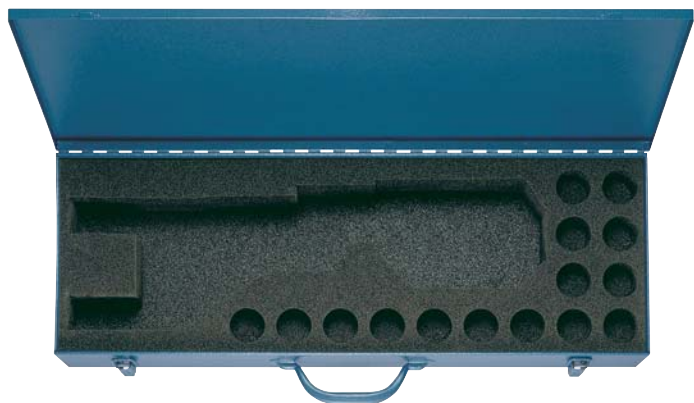

MK 120 U

for storage of crimping tool HK 120 U
and 11 pairs of crimping dies.
With lock and handle.

dimensions: 715 x 270 x 88 mm
weight: approx. 3.600 kg



STEEL CARRYING CASES **EMPTY**

MK U

for storage of hydraulic crimping tools
HK 12/2, HK 25/2, HK 45,
and for hydraulic cutting tools
K 502 and K 202, with additional
compartments for dies,
with lock and handle.

dimensions: 810 x 310 x 210 mm
weight: approx. 10.000 kg



STEEL CARRYING CASES **EMPTY**

MK 50

for storage of hydraulic cable cutters
HSG 45 resp. HSG 50.
With lock and handle.

dimensions: 615 x 270 x 68 mm
weight: approx. 3.000 kg



MK 85

for storage of hydraulic cable cutter HSG 85.
With lock and handle.

dimensions: 715 x 270 x 88 mm
weight: approx. 3.600 kg

