

LED machine luminaire



SPOT LED 003 - MCXFL 3 S



connected load
fitted with
work equipment
mains lead
luminaire body
material
surface
weight (net)
fastening

technology
usage
lamp cover
balance of articulation joints
system of protection
class of protection
colour luminaire body
special features
article no.

24 V; AC/DC
3 x Power-LED
without
approx. 3.0 m; with free stranded wires

aluminium
anodised
approx. 0,7 kg
screw-down flange~magnetic base (accessory)~table
clamp (accessory)~wall bracket (accessory)
switchable
without switch
glass screen
friction
IP 67
III
black
Spot with a 10° angle of radiation,
112459004

E_{min}: 164 lx
E_m: 3056 lx
E_{max}: 19959 lx

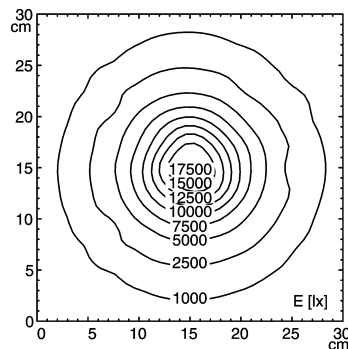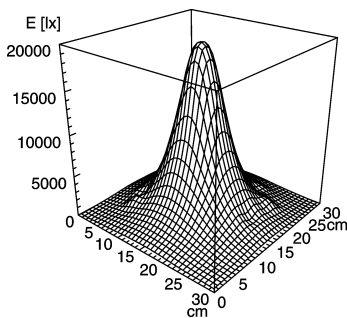

measuring conditions: d=50cm

