




## Product Sheet

Part Number: **CSHM 10**

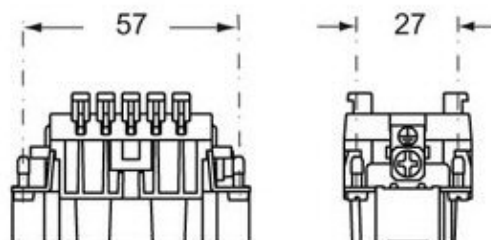

Dimensions in mm



<b>Family</b>	inserts
<b>Version</b>	Spring connection contacts SQUICH
<b>Series</b>	CSH
<b>Product type</b>	with male contacts
<b>Model</b>	male insert
<b>Reference standard</b>	EN 61984 (2001-11)
<b>Contact type</b>	silver plated
<b>No. of poles</b>	10 poles + 
<b>Voltage (V)</b>	500V
<b>Current (A)</b>	16A (A.C. and D.C.)
<b>Wire section</b>	0,14mm <sup>2</sup> - 2,5mm <sup>2</sup>
<b>Awg size</b>	26 - 14
<b>Quality mark</b>	
<b>IP degree of protection</b>	IP20 degree of protection without enclosure; IP65, IP66, IP68 (EN 60529) and IP69K (DIN 40050 - 9) with enclosure
<b>Fixing centre distance</b>	size "57.27"
<b>Impulse withstand voltage</b>	6kV
<b>Pollution degree</b>	3

The information and the dimensions are not binding and may be changed without prior notice.