

eFace 2025

High Definition 2.0M pixel WebCam



Enjoy the smoothest HD video recordings from a webcam yet. The eFace 2025 from Genius delivers 720P (1280 x 720) high definition video at 30 fps, the full steam rate; so you can record HD video easily with the best quality and upload to YouTube, then display them on Facebook, MySpace or Live Spaces! Contact your salesperson for more information.

Features:

- **Superior 2.0M pixel sensor** gives more details and definition without blurring and up to 8 mega pixel still image capture by software interpolation.
- **Premium multi-layer adjustable lens** allows you to manually control the subject focus without blurring.
- **HD video in 1280 x 720** at 30 fps, the full steam rate.
- **True Plug & Play**, no driver required.
- **Built-in microphone**
- **USB 2.0 interface:** transmit speed up to 480Mbps.
- **Foldable & portable design**, easy to carry.
- **Universal clip base** for LCD monitor, notebook or standalone.
- **Quick video upload** to YouTube using bundled CrazyTalk Cam Suite PRO.



No Driver required!



Date Available:

Delivery: July 20, 2009
Chain Store (MSRP):
US\$59.99
Non-Chain Store (MSRP):
US\$62.99

Bundled Software:



Capture




Image/Video capture for YouTube upload

Avatar Live/Magic Mirror



Change talking characters or facial expressions

Media/Desktop Share

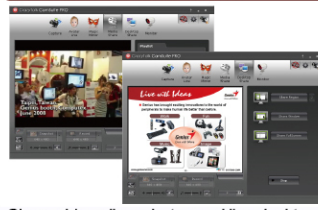

Share video clips, photos and live desktop activity without delay

Monitor



Motion detect and auto recording

Specifications:

Model Name	eFace 2025	eFace 1300
Product image		
Image Sensor	2.0M pixel CMOS	1.3M pixel CMOS
Lens type	Manual focus	Manual focus
Interface	USB 2.0	USB 2.0
File format	JPEG/WMV	JPEG/WMV
Still Image in CrazyTalk Cam Suite PRO	8MP (Software Interpolation), 1600 x 1200, 1280 x 1024, 1280 x 720, 800 X 600, 640 x 480, 352 x 288, 320 x 240, 176 x 144, 160 x 120 pixels	8MP (Software interpolation) 1280 x 1024, 1280 x 960, 800 x 600, 640 x 480, 352 x 288, 320 x 240, 176 x 144, 160 x 120 pixels
Video resolution	CIF/VGA: Up to 30fps 720P HD: Up to 30fps 1.3M: Up to 20fps 2.0M: Up to 6fps	CIF/VGA: Up to 30 fps 1.3M: Up to 8 fps
View angle	Up and Down: 100 degrees	Swivel 360 degrees Up and Down: 120 degrees
UVC (Plug & Play)	✓	✓
Built-in Microphone	✓	✓

System Requirements:

- **For PC**
 - Pentium 4 2.4 GHz or AMD equivalent
 - Windows 7/Vista/XP SP2 operation system
 - DirectX 9.0 above
- **For Mac**
 - 2.33 GHz Intel Core 2 Duo compatible
 - 1.07 GHz Power PC G4
 - Mac OS 10.4.9 above
- 512MB RAM
- 500MB HDD (1GB recommended)
- DVD-ROM for software installation
- Available USB port

Package Contents:

- eFace 2025 webcam
- CD-ROM includes:
 - CrazyTalk Cam Suite PRO
 - Multi-language user's manual
- Multi-language quick guide

WEEE information:

- Body Weight (g): 62g
- Body Size (LxWxH): 60 x 66 x 71 mm
- Giftbox Size (LxWxH): 163 x 52 x 220 mm
- PCs/ Carton: 20pcs/ Carton
- CUFT: 1.60 CUFT/ CTN (461 x 274 x 359 mm)
- P/N: 32200160101
- EAN: 4710268230939 / UPC: 091163230939