


# Tungsten Halogen

Lamps for headlights & auxiliary lighting

Reference No      Volt      Watt      Type      Dim(mm)


## H4

|             |     |        |    |      |
|-------------|-----|--------|----|------|
| <b>HB12</b> | 12v | 60/55  | H4 | P45t |
| <b>485</b>  | 12v | 100/80 | H4 | P45t |
| <b>495</b>  | 12v | 130/90 | H4 | P45t |
| <b>HB24</b> | 24v | 75/70  | H4 | P45t |
| <b>497</b>  | 24v | 100/80 | H4 | P45t |

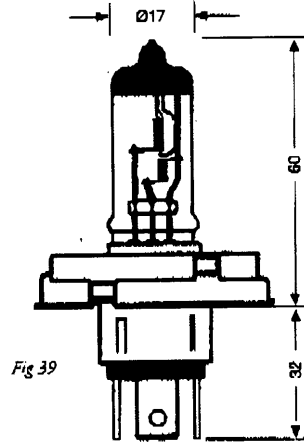


## H7

|            |     |     |    |       |
|------------|-----|-----|----|-------|
| <b>499</b> | 12v | 55w | H7 | Px26d |
| <b>498</b> | 24v | 70w | H7 | Px26d |

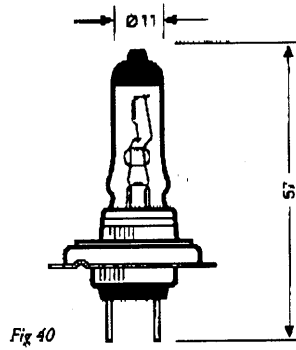

## BA9

|            |     |     |         |     |
|------------|-----|-----|---------|-----|
| <b>431</b> | 12v | 5w  | Halogen | BA9 |
| <b>432</b> | 12v | 10w | Halogen | BA9 |
| <b>433</b> | 12v | 20w | Halogen | BA9 |

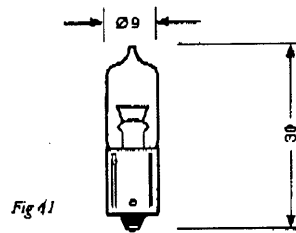

## PCB HALOGEN

|              |     |    |     |   |
|--------------|-----|----|-----|---|
| <b>64124</b> | 12v | 5w | PCB | 9 |
|--------------|-----|----|-----|---|

