

AC Centrifugal Blowers Dual Inlet, Ø146mm



ebm-papst Mulfingen


- Dual Inlet fans with an external rotor motor offering the advantage of matched motor and impeller in a compact space saving design.
- Motors: IP44 rated, sealed for life, maintenance free, class B insulation, precision ball bearings and side mounted capacitor and terminal block.
- Impeller: forward curved multi-vane type force fitted for vibration free operation/efficient cooling.
- Body: heavy duty, galvanised steel
- May be mounted in any position

Nominal Data		Curve	Voltage	Frequency	Air Flow	Speed/rpm	Power Input	Current Draw	Noise	Perm. Amb. Temp.	Mass
Part Number	Curve	VAC	HZ	M ³ /h	min ⁻¹	W	A	DB(A)	°C	kg	
D2E146-AP43-62	1	230	50	935	1650	245	1.08	60	40	4.2	
		230	60	690	2100	270	1.20	62	40		
D2E146-AP47-75	2	230	50	970	2050	300	1.31	63	40	4.2	
		230	60	690	2550	330	1.45	68	35		

AC Centrifugal Blowers

Dual Inlet, Ø146mm

Performance Curve

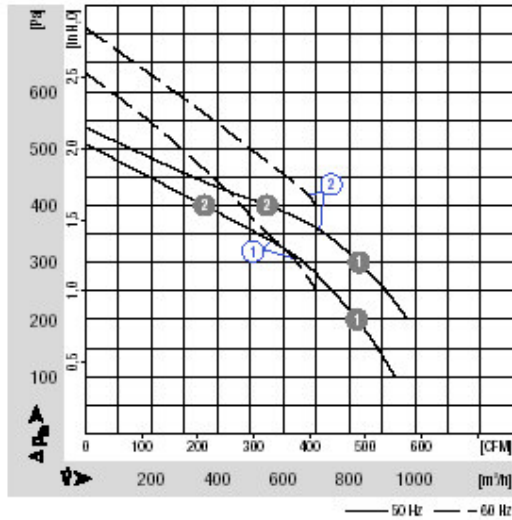

Dimensions

