




REINFORCED USB MEMORY KEYS




We provide reinforced USB memory keys available in different capacities. When mated, the system is IP67. Shells are metallic with 1/4 turn bayonet coupling.

Dimensions of rugged USBF Key:

ROHS COMPLIANT

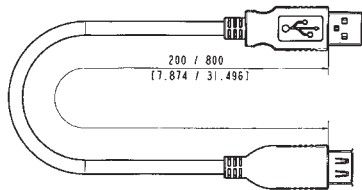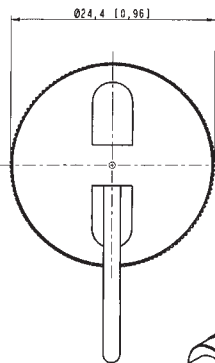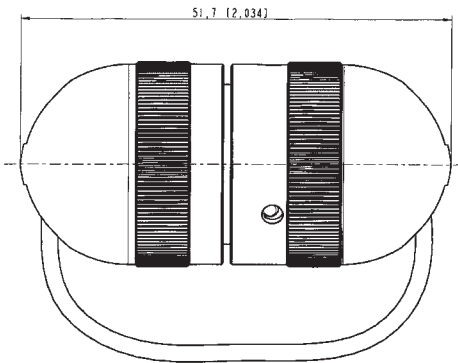

USB cordset is included with each memory key

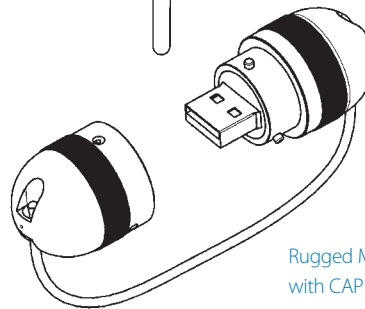

Rugged Metallic USB KEY with CAP SEALING : IP 67

DEFINITION OF PART NUMBER

USBF KEY

0256

N

Beginning of every USB Key part number. Remains unchanged.

Capacity of your USBF Key:
0256
0512
1024
Other capacity, please consult us at contact@rjfield.com

Shell finish:
N: Natural
G: Green
B: Black

EXAMPLE: **USBFKEY0256N**: USB MEMORY KEY - CAPACITY OF 256MO - SHELL FINISH : NATURAL

EXAMPLE: **USBFKEY1024G**: USB MEMORY KEY - CAPACITY OF 1024MO - SHELL FINISH : GREEN