


PRODUCT DATA SHEET

Type	Size	Rating	Description	Part No.
Incandescent	G11(G-3½)	6.5V 300mA	11mm Bayonet lamp	G502-5

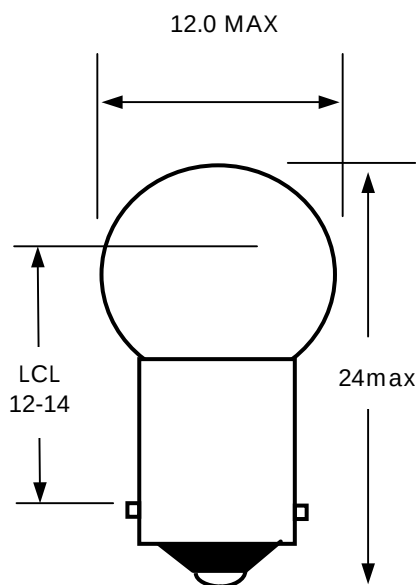

Dimension in mm.

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
6.5	270	300	330	10	12	14	4,000

NOTES:

- 1 RoHS compliant
- 2 Cap type BA9s/13, nickel plated brass
- 3 Filament shape C-2R
- 4 Cap marking CML 6.5V 300mA

Issue No.	Date	C.N. No.	Drawn	Tech	QA
1	29/08/07	-	BCW		