



# NEXUS


SLEEK AND SLIM,  
WITH SOFTLY ROUNDED  
CORNERS AND GENTLY  
CURVED ROCKERS,  
NEXUS COMBINES  
SUPERIOR QUALITY  
WITH STUNNING GOOD  
LOOKS AND EASY  
INSTALLATION.  
A STYLISH MODERN  
LOOK FOR THE HOME  
OR OFFICE.




ASHFORD  
ENGLAND

30 Year  
Guarantee


# NEXUS

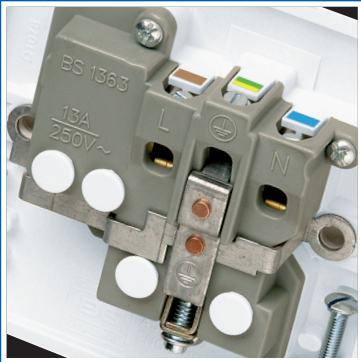


Angled in-line and colour coded terminals

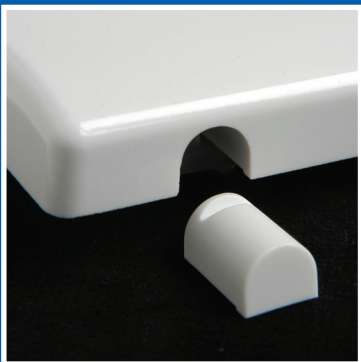

Removable flex outlet

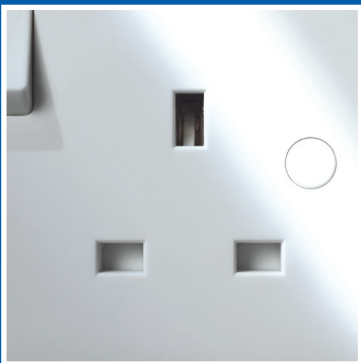


Screw covers for sleek appearance

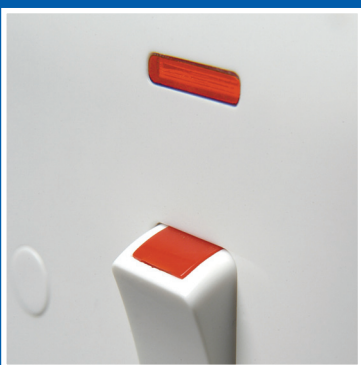


Modern slimline neon inlaid red rocker indicator



Modern slimline profile

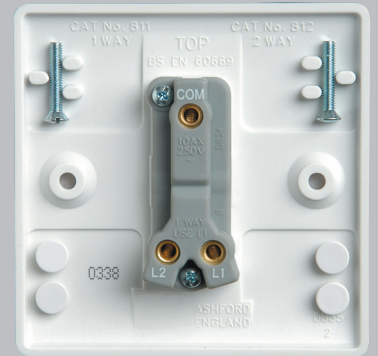




All light switches  
10AX rated

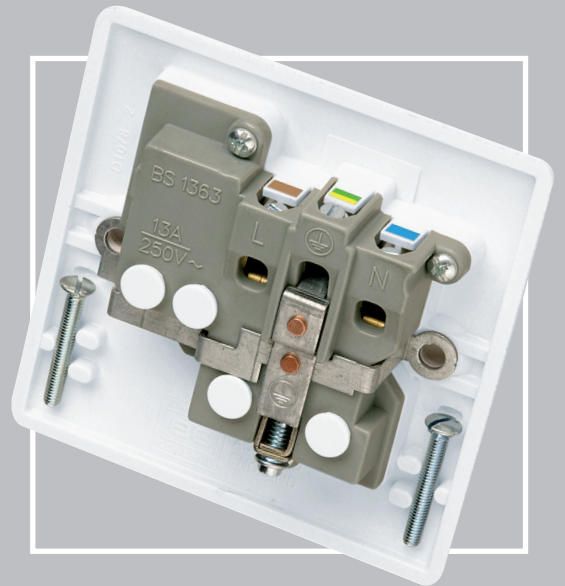

Large terminals  
Spare screw covers  
Retained screws



Retrofit spacer for easy installation during rewires

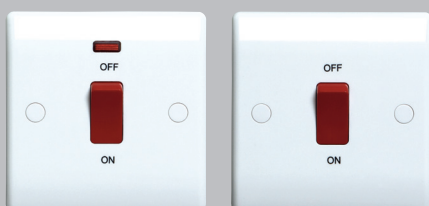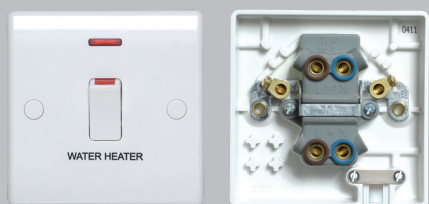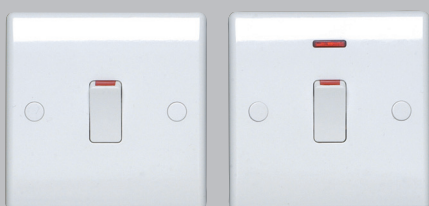

## 10AX PLATE SWITCHES

Code	Description	Carton Quantity	Trade Price £
811	1 Gang, 1 Way 10AX Switch	10	1.25
812	1 Gang, 2 Way 10 AX Switch	10	1.48
813	Intermediate 10 AX Switch	10	5.61
814	Bell Push	10	5.23
815	3 Pole Fan Isolator 10 AX Switch	10	5.69
842	2 Gang, 2 Way 10 AX Switch	10	2.80
843	3 Gang, 2 Way 10 AX Switch	10	4.50
844	4 Gang, 2 Way 10 AX Switch	5	8.50
846	6 Gang, 2 Way 10 AX Switch	5	14.50

Manufactured to BS EN 60669-1.

## 20A SWITCHES

Code	Description	Carton Quantity	Trade Price £
830	20A DP Switch	10	4.65
831	20A DP Switch with Neon	10	6.50
832	20A DP Switch with Flex Outlet	10	5.75
833	20A DP Switch with Neon and Flex Outlet	10	6.80
832WH	20A DP Switch, marked Water Heater with Flex Outlet	10	6.20
833WH	20A DP Switch, marked Water Heater with Neon and F/O	10	8.75

Manufactured to BS EN 60669-1.

## 45A SWITCHES





Code	Description	Carton Quantity	Trade Price £
870	45A DP Cooker Control Unit with 13A Socket and Neon	5	16.30
871	45A DP Cooker Control Unit with 13A Socket	5	15.80
872	45A DP Switch with Neon Large Plate	5	12.19
873	45A DP Switch Large Plate	5	11.72
874	45A DP Switch with Neon Single Plate	10	13.73
875	45A DP Switch Single Plate	10	11.48

Manufactured to BS 4177 and BS EN 60669-1. All units supplied with spacer plates.

## 45 AMP COOKER OUTLET

Code	Description	Carton Quantity	Trade Price £
879	45A Flex Outlet Plate Bottom Entry	10	5.55

Manufactured to BS 5733.

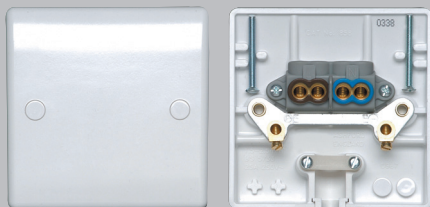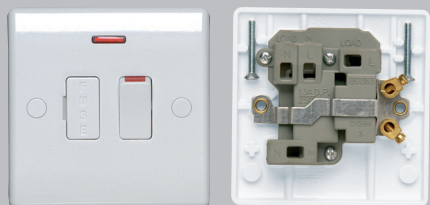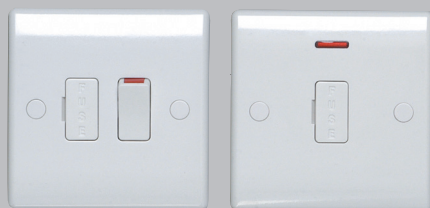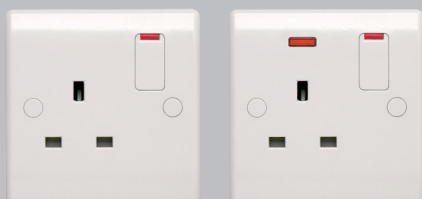

## 13 AMP SOCKET OUTLETS

Code	Description	Carton Quantity	Trade Price £
821SP	1 Gang 13A Single Pole Switched	10	2.97
821DP	1 Gang 13A Double Pole Switched	10	3.60
822SP	2 Gang 13A Single Pole Switched	5	5.05
822DP	2 Gang 13A Double Pole Switched	5	5.50
823	1 Gang 13A Unswitched	10	2.75
824	2 Gang 13A Unswitched	5	4.55
825	1 Gang 13A Switched With Neon	10	5.40
826	2 Gang 13A Switched With Neon	5	8.75

Manufactured to BS 1363 part 2.

## ROUND PIN SOCKET OUTLETS

Code	Description	Carton Quantity	Trade Price £
828	1 Gang 2A Unswitched Socket Round Pin	10	4.80
829	1 Gang 5A Unswitched Socket Round Pin	10	5.80
899	1 Gang 15A Switched Socket Round Pin	10	P.O.A.

Manufactured to BS 546.

## 13 AMP FUSED CONNECTION UNITS

Code	Description	Carton Quantity	Trade Price £
850	13A Switched and Fused	10	6.00
852	13A Switched and Fused with Neon	10	7.90
854	13A Unswitched and Fused	10	5.05
856	13A Unswitched and Fused with Neon	10	6.10

Manufactured to BS 1363 part 4.

## 13 AMP FUSED CONNECTION UNITS WITH FLEX OUTLET

Code	Description	Carton Quantity	Trade Price £
851	13A Switched and Fused with Flex Outlet	10	6.28
853	13A Switched and Fused with Neon and Flex Outlet	10	8.68
855	13A Unswitched and Fused with Flex Outlet	10	5.78
857	13A Unswitched and Fused with Neon and Flex Outlet	10	6.90

Manufactured to BS 1363 part 4.

## 25 AMP FLEX OUTLET PLATE


Code	Description	Carton Quantity	Trade Price £
858	25A Flex Outlet Plate Bottom Entry	10	3.75

Manufactured to BS 5733.

## SHAVER SOCKET

Code	Description	Carton Quantity	Trade Price £
820	115/230V Dual Voltage Shaver Socket	5	21.65

Manufactured to BS EN 61558-1.

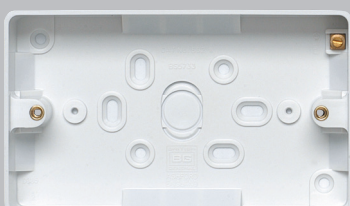

## CO-AXIAL, SATELLITE AND TRIPLEX OUTLETS

Code	Description	Carton Quantity	Trade Price £
860	1 Gang Co-axial Socket	10	4.45
861	2 Gang Co-axial Socket	10	5.11
862	1 Gang Isolated Co-axial Socket	10	8.93
863	2 Gang Isolated Co-axial Socket	10	11.56
864	1 Gang Satellite Socket	10	5.70
865	2 Gang Satellite and Co-axial Socket	10	5.75
866	2 Gang Diplex TV/FM	10	10.52
867	3 Gang TV/FM/SAT Triplex	10	14.40
868	Triplex with BT Outlet and Co Axial Return	5	28.00

Manufactured to BS 3041 and BS 5733 where applicable.

## TELEPHONE & DATA OUTLETS

Code	Description	Carton Quantity	Trade Price £
8BTM/1	1 Gang Telephone Socket Master	10	7.10
8BTM/2	2 Gang Telephone Socket Master	10	8.95
8BTS/1	1 Gang Telephone Socket Slave	10	5.68
8BTS/2	2 Gang Telephone Socket Slave	10	7.48
8RJ45/1	1 Gang RJ45 Data Outlet Socket	10	12.25
8RJ45/2	2 Gang RJ45 Data Outlet Socket	10	29.95
8RJ11/1	1 Gang RJ11 Telephone Socket	10	10.25
8RJ11/2	2 Gang RJ11 Telephone Socket	10	26.95

Manufactured to BS 6312 part 2 where applicable.

Modules available to make up any combination of RJ11, BT and RJ45 outlets

## DIMMERS

Code	Description	Carton Quantity	Trade Price £
881	1 Gang 2 Way Push 400W	10	12.95
882	2 Gang 2 Way Push 400W	10	23.26
883	3 Gang 2 Way Push 400W	5	41.12
884	4 Gang 2 Way Push 400W	5	52.23

Manufactured to BS EN 60669. All dimmers are supplied with spacer plates.

## SURFACE BOXES AND BLANK PLATES

Code	Description	Carton Quantity	Trade Price £
817	1 Gang 10mm Square Spacer	20	0.80
818	2 Gang 10mm Rectangular Spacer	10	1.00
891	1 Gang Surface Box 32mm	10	1.08
892	2 Gang Surface Box 32mm	5	1.80
893	1 Gang Surface Box 19mm	10	1.00
894	1 Gang Blank-plate	20	0.90
895	2 Gang Blank-plate	10	1.70
896	Dual Surface Patress Box 37mm	5	2.85
877	1 Gang Surface Box 50mm	10	1.96
878	2 Gang Surface Box 50mm	5	2.55

Manufactured to BS5733.



# NEXUS

BG Electrical Ltd  
Unit 1,  
Highpoint Business Village,  
Henwood Industrial Estate,  
Ashford, Kent  
TN24 8DH

Tel: +44(0)1233 668000  
Fax: +44(0)1233 668100  
[www.bgelectrical.co.uk](http://www.bgelectrical.co.uk)  
[sales@bgelectrical.co.uk](mailto:sales@bgelectrical.co.uk)

