


## 19" complete chassis from aluminium, plain top cover and base plate



Photo shows 1 U

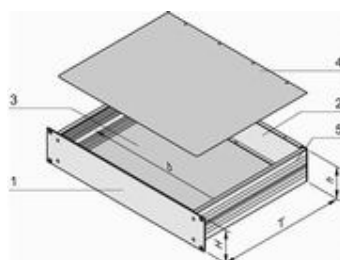

h = clear height (overall) (H - 8.1 mm)  
b = clear installation width = 403 mm

Part no.: 20860-605

## Features:

- Complete chassis from aluminium
- Detachable rear panel for easy machining
- EMC shielding of approx. 30 dB(A) at 1 GHz (without additional shielding material)
- In accordance with standard IEC 60297-3-100, -101, -105



NEW PRODUCT



## Technical information:

Description	Height	Height H	Depth T
Solid top cover and base plate	2 U	88.1 mm	280 mm

## Downloads:

3D PDF with CAD data (STEP/DWG/DXF/PDF) ([Log in](#) Required) 

User manual ([Log in](#) Required)

EMC / HF test report ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).  
If you do not yet have a user name, you may [Register here](#).

## Delivery comprises: Kit

Item	Qty	Description
1	1	Front panel, Al extrusion, 3 mm; front and rear side of front panels clear passivated
2	1	Rear panel, Al, 2 mm, etched
3	1	Base plate, plain, Al, 1 mm
4	1	Cover plate, plain, Al, 1 mm
5	2	Side panel, Al extrusion, raw; with grooves for threaded insert (2 × 7)
6	1	Assembly kit

## Accessories:

Part no.	Description	
<a href="#">20860-257</a>	Front handles incl. assembly kit for 2 U, Al extrusion, anodised, PU 2 pieces	<a href="#">Add to basket</a>

**20860-130**

EMC gasketing kit  
Silicone/nickel gasket 2100 mm for contacting side  
panel/cover plate; Seal, stainless steel, for front  
panel/cover plate, 1 kit

**Add to basket**