




Products for tomorrow...

Headquarter Europe
MEDER electronic AG
Friedrich-List Strasse 6
D-78234 Engen-Welschingen
Tel.: +49(0)7733-9487-0
Fax: +49(0)7733-9487-32
eMail: info@meder.com
Internet: www.meder.com


Headquarter USA
MEDER electronic Inc.
766 Falmouth Rd
Mashpee, MA 02649
Phone: +1/ 508-539-0002
Fax: +1/ 508-539-4088
eMail: salesusa@meder.com

Magnet: AlNiCo 500 4 x 19
Part Number: 4003004003

Dimensions (mm)

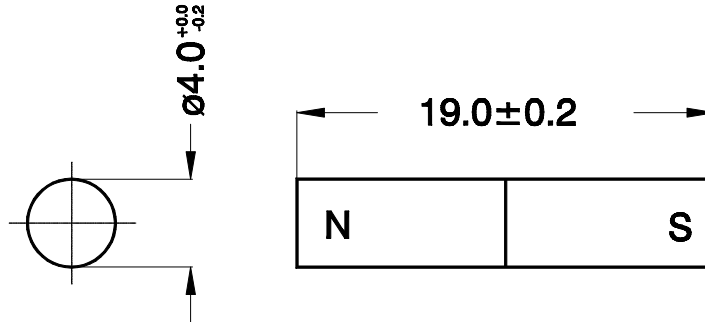

round bar magnet magnetization axial

 

AlNiCo 500 code acc. to DIN 17410 : 35 / 5

Magnetic values acc. to DIN 17410		Min.	Typ.	Max.	unit
Energy product	(B x H) max.	35	39,8	-	kJ/m^3
Remanence	B_r	1120	1240	-	mT
revers. temp. coeff. of B_r		-	-0,02%	-	%/K
Coercivity	H_{cB}	47,0	51,3	-	kA/m
Coercivity	H_{cJ}	48,0	51,7	-	kA/m
revers. temp. coeff. of H_{cJ}		-	-	-	%/K
Density		-	7,4	-	g/cm^3
max. operating temperature		-	-	450	$^{\circ}\text{C}$

Remark : all details correspond to manufacturers information

Magnetic Moment	M	1,98	2,22	-	$\text{X}10^{-5}$ Vs-cm
-----------------	---	------	------	---	----------------------------

DEFINITION:

$M = \Phi \cdot K$

Φ = Magnetic Flux

K = Coil Constant