



Products for tomorrow...


Headquarter Europe
 MEDER electronic AG
 Friedrich-List Strasse 6
 D-78234 Engen-Welschingen
 Tel.: +49(0)7733-9487-0
 Fax: +49(0)7733-9487-32
 eMail: info@meder.com
 Internet: www.meder.com

Headquarter USA
 MEDER electronic Inc.
 766 Falmouth Rd
 Mashpee, MA 02649
 Phone: +1/ 508-539-0002
 Fax: +1/ 508-539-4088
 eMail: salesusa@meder.com


Magnet: SmCo₅ 5,0 x 4,0

Part Number: 4003004026

Dimensions (mm)

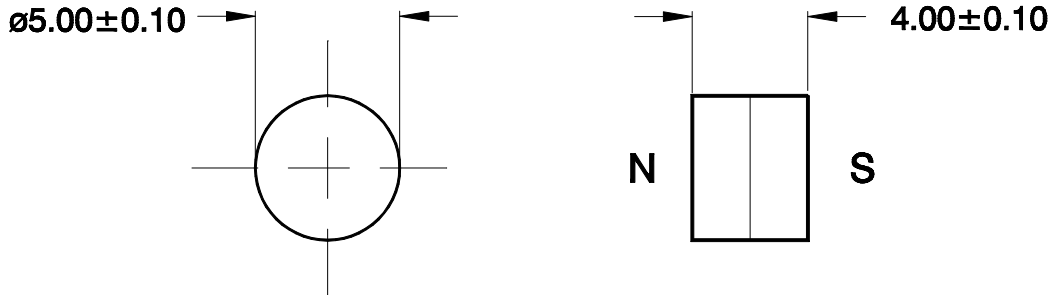

round bar magnet magnetization axial

 

SmCo₅ code acc. to DIN 17410 : 160 / 175 h

Magnetic values acc. to DIN 17410		Min.	Typ.	Max.	unit
Energy product	(B x H) max.	160	170	-	kJ/m ³
Remanence	B _r	900	925	-	mT
revers. temp. coeff. of B _r		-	-0,042	-	%/K
Coercivity	H _{cB}	680	710	-	kA/m
Coercivity	H _{cJ}	1750	2000	-	kA/m
revers. temp. coeff. of H _{cJ}		-	-0,25	-	%/K
Density		-	8,3	-	g/cm ³
max. operating temperature		-	-	250	°C

Remark : all details correspond to manufacturer information

Magnetic Moment	M	-	7,08523	-	X10 ⁻⁶ Vs·cm
-----------------	---	---	---------	---	----------------------------

DEFINITION:

M = Φ · K

Φ = Magnetic Flux

K = Coil Constant