


474-307, 474-319, 474-356

**HF - Series (IP 65)**


**Standard models**

**Flexible arm 250 mm**

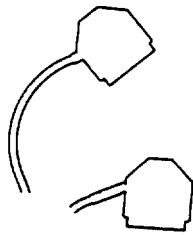


- Without joint ● 50W
- 75W
- 50W
- 75W
- With joint ● 50W
- 75W
- 50W
- 75W

**Flexible arm 500 mm**

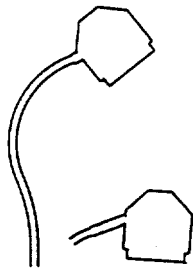


- Without joint ● 50W
- 75W
- 50W
- 75W
- With joint ● 50W
- 75W
- 50W
- 75W

**Flexible arm 700 mm**

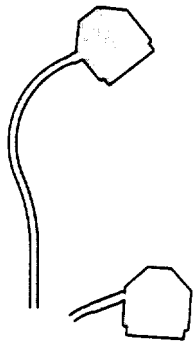

- Without joint ● 50W
- 75W
- 50W
- 75W
- With joint ● 50W
- 75W
- 50W
- 75W

**Jointed arm 250+400 mm**

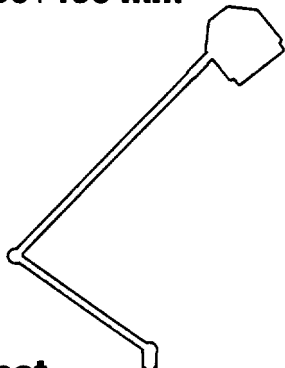

- 50W
- 75W
- 50W
- 75W

**Spot**



- Single joint ● 50W
- 75W
- 50W
- 75W



- Double joint ● 50W
- 75W
- 50W
- 75W



Base without transformer			
12V	24V		
12400	12600		
12500	12700		
12401	12601		
12501	12701		
12410	12610		
12510	12710		
12411	12611		
12511	12711		
12420	12620		
12520	12720		
12421	12621		
12521	12721		
12430	12630		
12530	12730		
12431	12631		
12531	12731		
12440	12640	474-307	
12540	12740		
12441	12641		
12541	12741		
12450	12650		
12550	12750		
12451	12651		
12551	12751		
12470	12670		
12570	12770		
12471	12671		
12571	12771		
12460	12660		
12560	12760		
12461	12661		
12561	12761		
12462	12662	474-319	
12562	12762		
12463	12663		
12563	12763		

**Accessories**

<b>Panel bracket</b>	250 mm ●	15540
<b>Fitted to flexible arm</b>	500 mm ○	15541
	700 mm ●	15550
	○	15551
	○	15560
	○	15561
<b>Trolley base</b>	●	14024
	○	14025
<b>Magnetic base</b>	●	12010
<b>Wall bracket</b>	●	14030
	○	14031
<b>Screw-clamp bracket</b>	●	14020
	○	14021
<b>Dimmer</b>		
<b>Fitted in base</b>		
	AC/DC, 12/24V, 20-35W	14081
<b>Switch</b>		
<b>Fitted to lamp head</b>		12095
<b>Handle</b>		
<b>Fitted to lamp head</b>		12096
<b>Protective transformer</b>		
IP-23	230V/12V- 80VA	12030
IP-23	230V/24V- 80VA	12035
<b>Distributor insert x 3</b>		
<b>For 12030/12035</b>		12040
<b>Plug-in-transformer</b>		
IP-20	230V/11,5V- 50VA	12045
IP-20	230V/24V- 50VA	12050
<b>For lenses, bulbs, reflectors and moisture/dust seal, see spare-part list pp. 10 - 12</b>		


● = Standard colour black  
○ = Standard colour white

# HF - Series

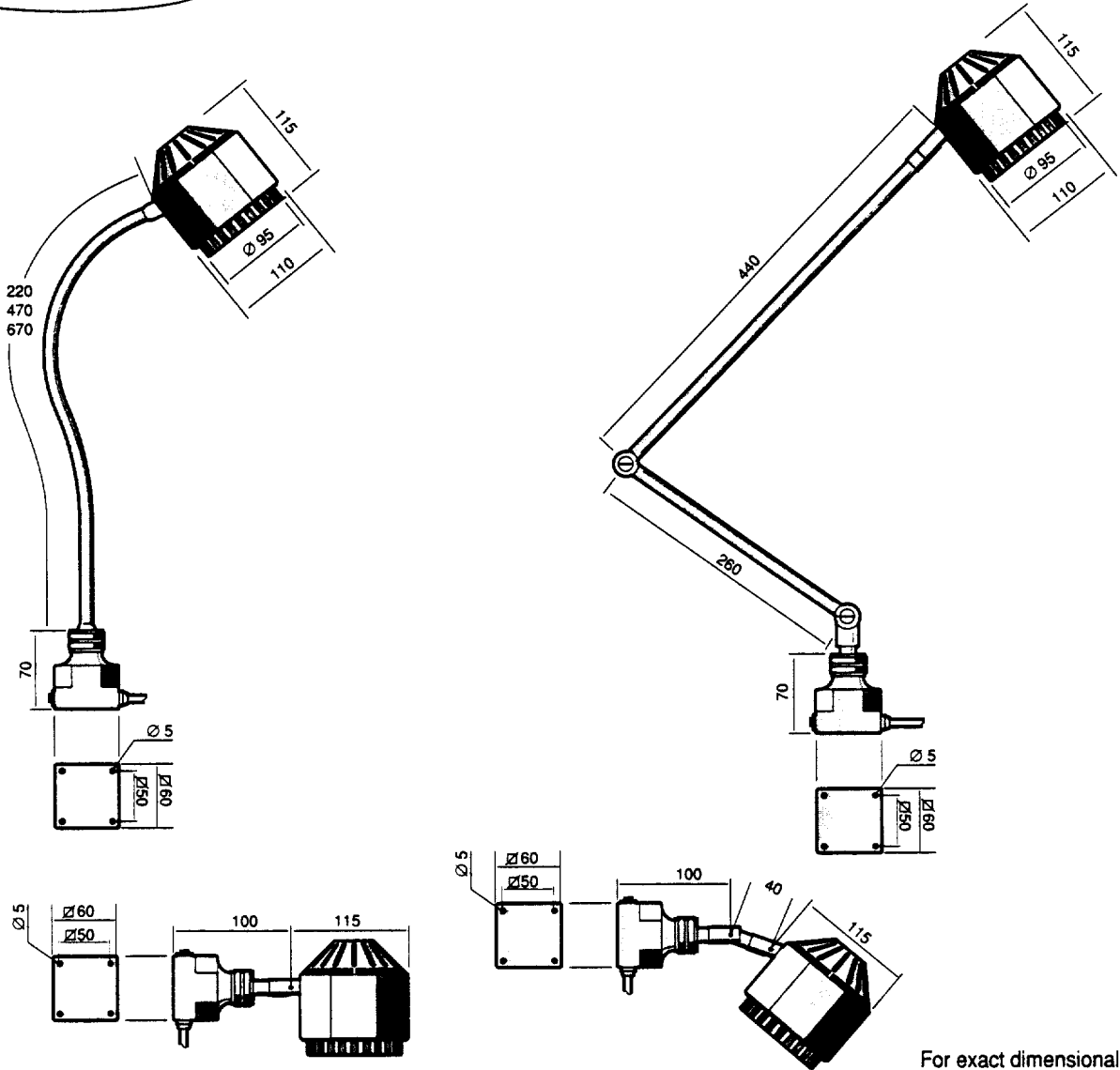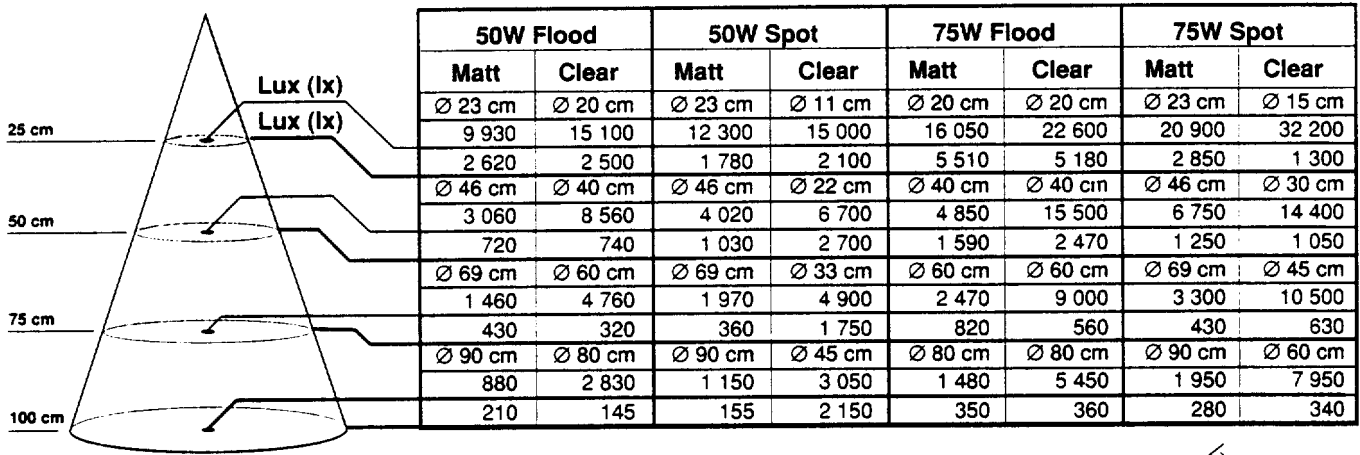


For exact dimensional data contact Sunnex.


## Trolley base

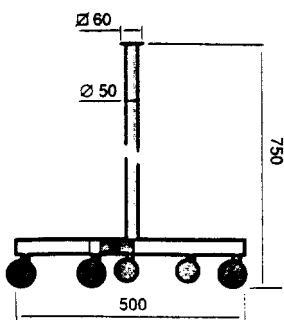


## Magnetic base

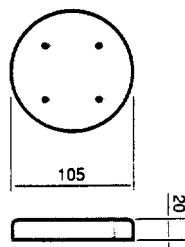

## Screw-clamp bracket

 

## Wall bracket

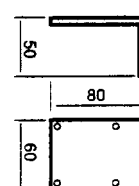

## Panel mounting

