


- Signal device for the 22,5 mm control panel programme
- Low current consumption
- High protection rating IP 65

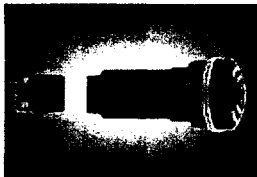

TECHNICAL SPECIFICATIONS:

Dimensions (Diameter x Depth):	28,2 mm x 68,8 mm		
Housing:	PA-GF, black		
Audio frequency:	c. 2400 Hz		
Tone type:	Continuous tone or pulse tone with approx. 1 Hz		
Current consumption:	≤ 8 mA		
Duty cycle:	100 %		
Fixing:	Installation mounting for ø 22,5 mm (M 22)		
Connection:	Connector plug with screwable connection max. 1,5 mm²		
Life duration:	> 5.000 h		

ORDER SPECIFICATIONS:



Voltage	24 V ≐	115 V ≐	230 V ~
Continuous tone	107 000 75	107 000 77	107 000 68
Pulse tone	107 010 75	107 010 77	107 010 68

TECHNICAL DIAGRAMS

see page 108



 107 Electronic Installation Buzzer

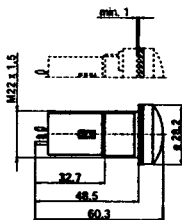

connectors 2 x 1,5mm

2 x terminal screws M3 with wire protection

