


Terminals

L1001/1 Terminal

This terminal incorporates a non-rotating centre disc in the head for lettering. The rotating collar is captive and the clamping gap is free from thread.

When used with Panel fittings 01 this terminal is panel sealed.

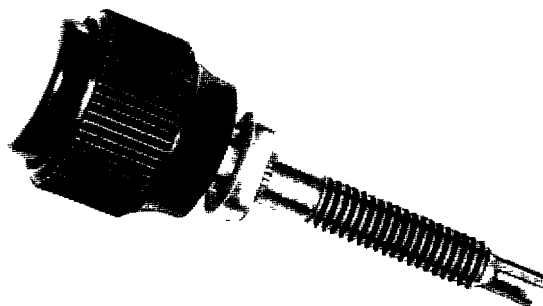

Current rating: 15 A

Temperature range: -25 °C to + 70 °C

Materials: Head, phenolic resin
Disc, tenite butyrate
Stem, brass, nickel-plated

Colours head: Black
disc Black, red


Ordering reference:

L1001/1/Colour

Fixing Kit 3

Panel fittings (see below and opposite)

(Terminals and fittings are supplied unassembled and must be ordered as individual items.)

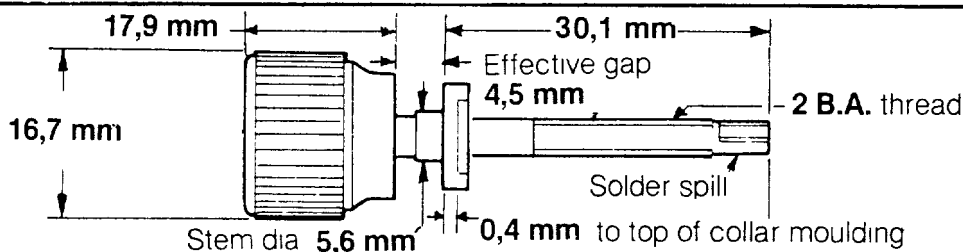

Fixing kit 3

Comprises: Metal washer
Non-rotating washer
2 locknuts (2 BA)

427-329.

B panel fittings

Comprises: Phenolic resin
moulding SRBP
insulating washer

Breakdown voltage: 3 kVd c

Insulation resistance: $\geq 10^3$ megohms

Temperature range: -40 °C to + 85 °C
(ambient)

Fixing torque: 1,41 Nm

Colour: Black

