



304 3149

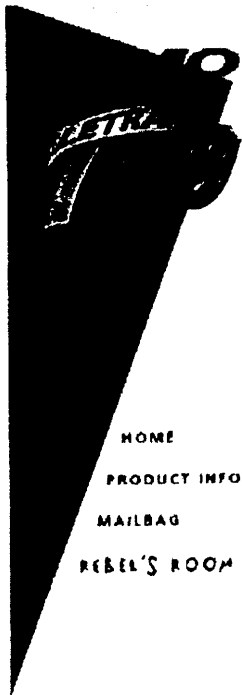

Technical detail

— LABELS • PRODUCT INFO

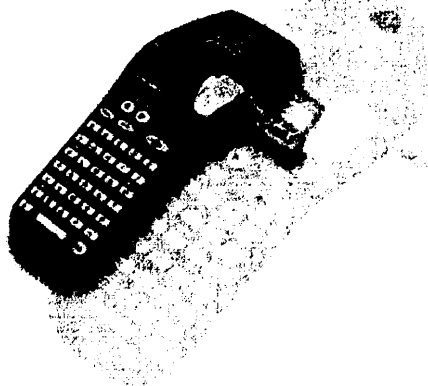

Printing

Print type: Direct Thermal
 Print Resolution: 160 DPI
 Print line: (max height) 0.19" (4.7 mm)
 Max. character height: 0.19" (4.7 mm)
 No. of Dots: 30
 Print lines: 2
 Print speed: 0.27" per sec (6.8 mm/s)

* Tapes

Tape widths: 0.5" (12 mm)
 Cassette type: LetraTag

Keyboard

Layout: Portrait / ABC
 No. of keys: 40

Display

No. of characters: 6.5
 No. of lines: 1
 No. of annunciators: 6
 Viewing area: 1.2" x 0.4" (30 x 10 mm)

Character Set

No. of characters: 154
 No. of font: 1
 Symbols: Yes
 Sizes: 4 character sizes
 Styles: 5 - Normal, Vertical, Outline, Shaded
 includes combinations (ie vertical italics, etc)

Software

Print preview: Yes
 Welcome: Yes

Max Label Length

No. of characters: 72

Memory

Last label: Yes

Cutting

Tape Cut: Manual

Power

No. of batteries: 6
 Battery type: LR6 (AA size)

Dimensions

Thickness: 2.4" (60 mm)
 Width: 3.1" (78 mm)
 Length: 8.1" (205 mm)
 Weight: 0.63lb (300 g) excl. batteries & tape