


E-Z-CODE®

Printed Labels in Pocket Book Format

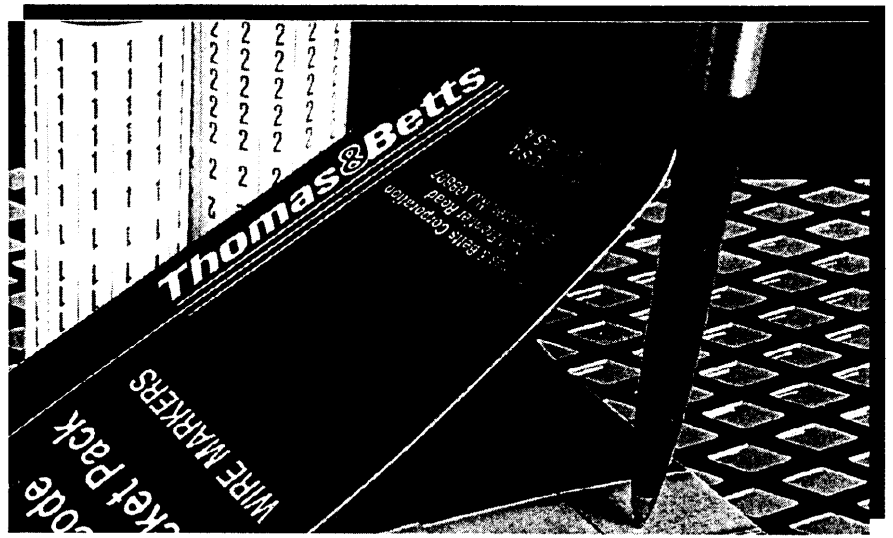

Product Description

Self-adhesive labels in pocket book format
 Number per book: up to 460 labels for cables
 Cardboard protective cover

Material

WBC vary-temp fabric tape can be used in temperature range of -35 °C to +95 °C.
 Adhesion to steel: 7N/mm

Dimensions

Book: 15 x 8 cm (L x W)
 Label: 5 x 31 mm (WC-?-D)
 Individual: 5 x 5 mm


Product Advantages

Ideal and easy application due to:

- Cardboard book cover protects contents
- Strip at margin for non-contact processing and, if desired, temporary labeling
- Single perforation per strip for identifying contact
- Material stable at high temperatures with high mechanical and chemical resistance
- Insensitive to moisture and oil
- High permanent adhesive strength
- Convenient size
- Black lettering on white background makes it easy to read

Typical Areas of Application

The pocket book form is ideal for the electronic specialist in installation, repair and maintenance work

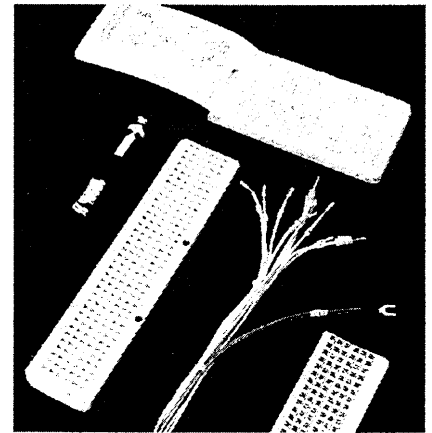

Prod.-No. (Pocket book)	Print	Number of labels per book
WM-0-9	0 - 9 + L1, L2, L3	each 40 + each 20
WM-0-45	0 - 45	each 10
WM-46-90	46 - 90	each 10
WM-A-Z	A - Z, +, - and 0 - 15	each 10
WM-123	1, 2, 3	each 150
WM-ABC	A, B, C	each 150
WM-A-33	1 - 33, A, B, +, - + L1, L2, L3	each 10 + each 20
WM-A-90	0 - 45, 46 - 90 + L1, L2, L3	each 4 + each 2
WM-UVM	U, V, W and ±	each 110
	Choice of print	
WM-?	0 - 9 A, B, C, D, E, F G, L, N, P, R, S, T, X	each 460

Ordering note: When ordering „?“, fill in symbol for the chosen product. Example: WM-7 contains labels with number 7.