 
 
 

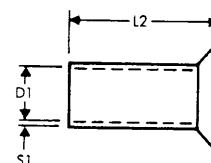


Continued from page 13

CODE T (FRENCH)		CODE W (GERMAN)		Sizes mm						
Part Number	Colour	Part Number	Colour	mm2	d1	S1	d3	S2	L1	L2
DICE0035 	Red	PET0035 	Beige	35	8.3	0.3	12.7	0.4	28.0	16.0
DICE0035/L 		PET0035/L 								25.0
DICE0050 	Blue	PET0050 	Olive	50	10.3	0.3	15.0	0.5	34.0	20.0
DICE0050/L 		PET0050/L 								25.0
DICE0070 	Yellow			70	13.5	0.3	16.0	0.5	35.0	20.0
DICE0095 	Red			95	14.5	0.7	16.0	0.5	42.0	25.0

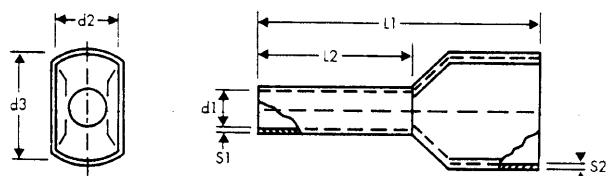

CORD END TERMINALS (INSULATED WITH PARALLEL SLEEVE)

Code		Sizes mm							
Part Number	Colour	mm ²	d1	S1	d3	d2	S2	L1	L2
DICE2005	White	2 x 0.5	1.5	0.15	5.6	3.6	0.25	15.0	8.0
DICE2075	Grey	2 x .75	1.8	0.15	6.2	3.6	0.75	15.0	8.0
DICE2010	Red	2 x 1.0	2.0	0.15	6.0	4.0	0.30	15.0	8.0
DICE2015	Black	2 x 1.5	2.3	0.15	7.2	4.2	0.30	16.0	8.0
DICE2025	Blue	2 x 2.5	2.9	0.15	8.5	5.0	0.30	18.0	10.0
DICE2040	Lt Grey	2 x 4.0	3.8	0.20	9.2	5.7	0.35	23.0	12.0
DICE2060	Yellow	2 x 6.0	4.9	0.20	10.5	6.8	0.35	24.0	14.0
DICE2100	Red	2 x 10.0	6.5	0.20	13.0	8.0	0.40	26.0	14.0
DICE2160	Blue	2 x 16.0	8.7	0.20	19.3	10.5	0.40	31.0	14.0

Suitable Crimping Tools
DCER 510 DCER 1635 DCE 025 DCE 516

CORD END TERMINALS (NON INSULATED)

In accordance with DIN Standard 46228 Part 1.
Suitable for **Tri-rated cables**.

Part Number	Cable Size mm ²	L2	D1	S1
DUCE0505	.5	6.00	1.00	0.15
DUCE7575	.75	10.00	1.4	0.15
DUCE1010	1.00	10.00	1.6	0.15
DUCE1515	1.50	10.00	1.8	0.15
DUCE2525	2.50	12.00	2.3	0.15
DUCE4040	4.00	12.00	2.8	0.20
DUCE6040	6.00	15.00	3.6	0.20
DUCE0010	10.00	15.00	4.5	0.20
DUCE0016	16.00	15.00	5.8	0.20
DUCE0025	25.00	15.00	7.3	0.20
DUCE0035	35.00	20.00	8.3	0.30
DUCE0050	50.00	22.00	10.3	0.30
DUCE0070	70.00	26.00	12.6	0.30
DUCE0095	95.00	30.00	15.2	0.40