


Low Impedance Horn Speakers

- 284-968

ECONOMY RANGE ROUND 8Ω

With adjustable fixing bracket.
Grey aluminium.


- P106 (CH66) 15W
- P107 (CH100) 25W
- P108 (CH120) 40W

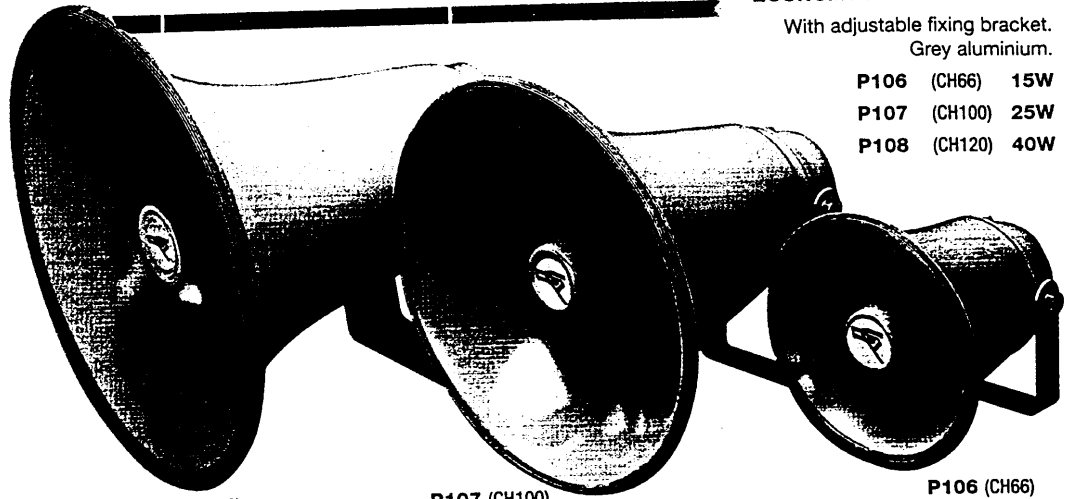

CONTRACT RANGE ROUND 8Ω

Top grade plastics, adjustable metal U-bracket for wall or ceiling mounting.

- P630M (HR610) 10W
- P630T (HR815) 15W
- P631 (HR830) 30W

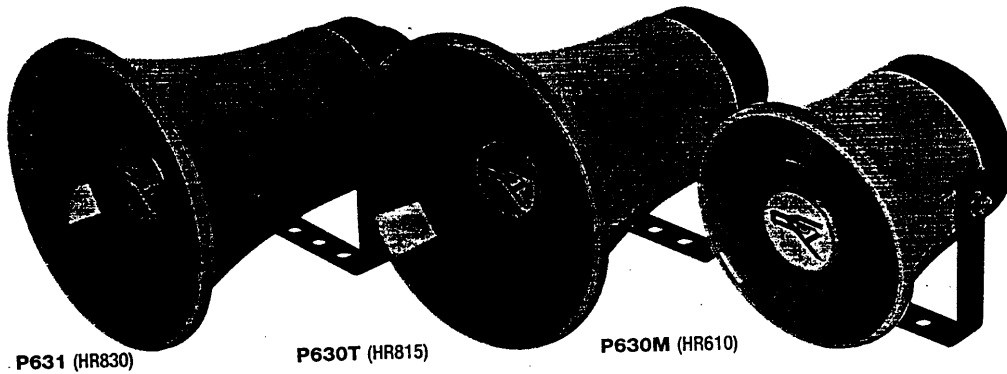


SQUARE 8Ω

With metal bracket for wall or ceiling mounting.

- P112 (HDB15E) 15W
- P113 (HDB25E) 25W

P113 (HDB25E)

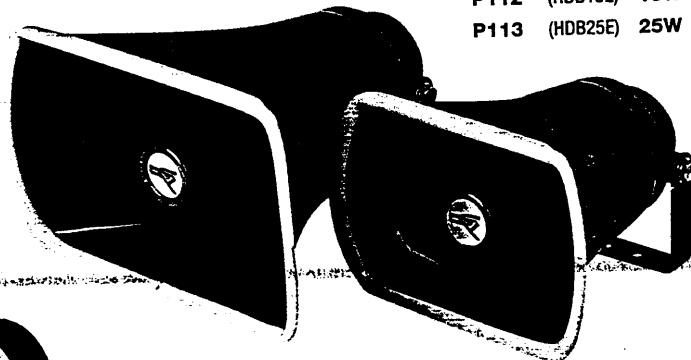

P112 (HDB15E)

P628 (HDB12)
30W SQUARE 8Ω

High quality flared horn, top grade ABS mouldings with strong metal bracket for wall, ceiling or vehicle roof mounting.

P627T (HDB8N)
20W SQUARE 8Ω

As P628 but 20 Watts.

P627M (HDB4) 4W SQUARE 8Ω

Compact square speaker with adjustable pedestal. Plastic.

	P106	P107	P108	P630M	P630T	P631	P112	P113	P627M	P627T	P628
Power handling watts rms	15	25	40	10	15	30	15	25	4	20	30
SPL @ 1m, dB(A), max	113	115	117	110	112	114	111	113	106	118	120
Per W	101	101	101	100	102	100	100	100	100	105	105
Per W @ 45°	96	96	96	98	98	98	94	94	95	99	99
Frequency response	450-2500Hz	400-2500Hz	300-2500Hz	200-13000Hz	200-9000Hz	200-11000Hz	300-4000Hz	300-5000Hz	500-8000Hz	350-7000Hz	250-7000Hz
Dimensions dia. x depth (exc. bracket) mm.	160x160x150	259x259x242	310x310x262	154x154x192	210x210x250	210x210x250	150x215x200	173x270x255	118x118x112	148x230x228	162x312x300