


724 490

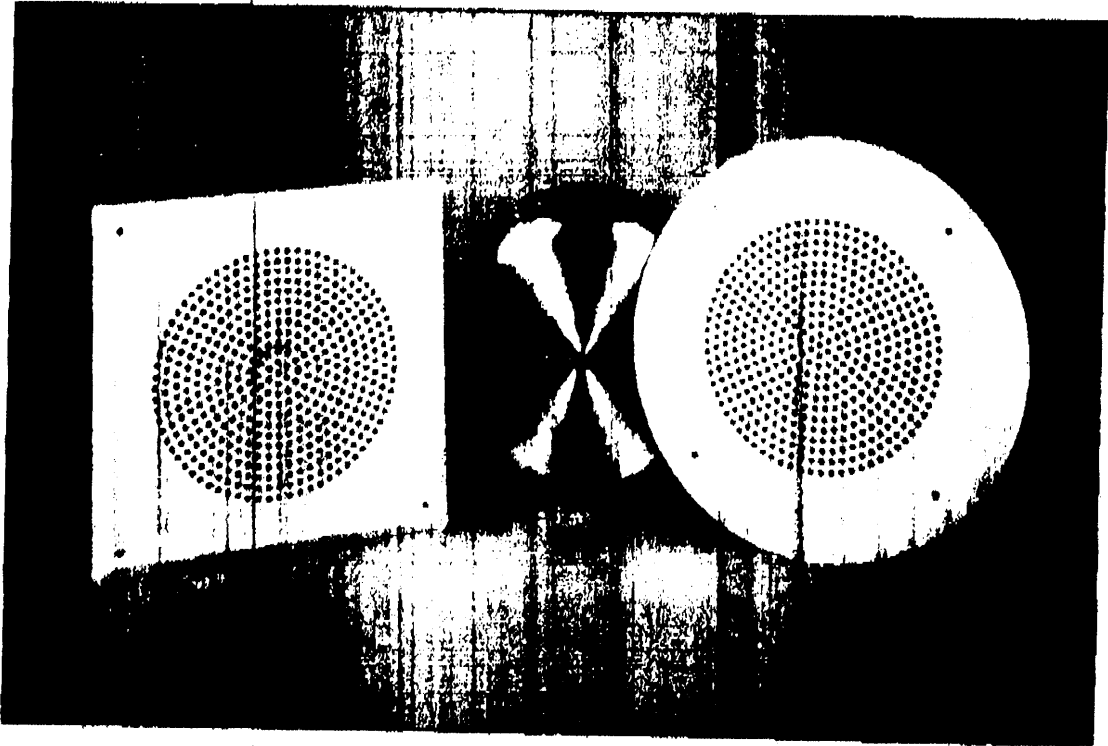

<u>Model</u>	<u>CS4/T</u>	<u>LS00003</u>
Input (100V)	4W	4W
Loudspeaker Impedance	8ohms	8ohms
Transformer Tappings	4.2, 1 1/2, 1/4, 1/8 W	4.2, 1 1/2, 1/4, 1/8 W
SPL 1W/1M Pink Noise	94dB	94dB
SPL Rated Power/1M	100dB	100dB
Frequency Range	80-14KHz	80-14KHz
Loudspeakers	1x203mm	1x203mm
Dimensions (ØxD) Without Fire Dome	244x244x78mm	213x78mm
Ceiling Cut Out Ø	218mm	218mm
Weight	1.1kg	1.1kg
Material	Mild Steel	Mild Steel
Standard Finish	White RAL9010	White RAL9010
Fire Dome	<u>FDL</u>	<u>FDL</u>
Fire Dome Material	Aluminium or Mild Steel	Aluminium or Mild Steel
Dimension (ØxD) With Fire Dome	244x244x95mm	213x95mm

Grilles can be finished in any RAL or BS Colour
Available with discreet volume controls

ETAL CEILING SPEAKERS